

12TW75-7

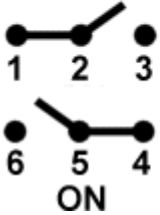
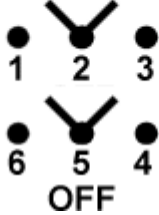
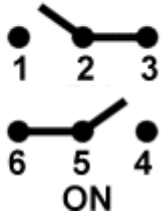
([Home](#) : [Products](#) : [basics](#) : [Sw itches](#) : [MICRO SWITCH™ Toggle Sw itches](#) : [TW](#))



TW Series Toggle Switch, 2 pole, 3 position, Solder T2 Type terminal, Standard Lever

Actual product appearance may vary.

Product Specifications

Product Type	MICRO SWITCH™ Toggle Sw itch
Ampere/Voltage Range (Resistive Load)	0.1 A to 5.0 A at 0.5 Vac to 115 Vac 0.1 A to 5.0 A at 0.5 Vdc to 28 Vdc
Circuitry	DPDT
Action	3 position
Circuitry/Operating action	<div><div><div>Keyway Momentary Position</div><div></div></div><div><div>Center Position</div><div></div></div><div><div>Opposite Keyway Momentary Position</div><div></div></div></div>
Mounting	Bushing 15/32 in
Termination	Solder T2 type
Lever Type	Standard
UL/CSA	L117: 5 A at 125 Vac
Comment	Fine silver contacts
Availability	Global
UNSPSC Code	39122211
UNSPSC Commodity	39122211 Toggle Sw itch
Series Name	TW

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[12TW75-7](#)