


4TL887-2D

([Home](#) : [Products](#) : [basics](#) : [Sw itches](#) : [MICRO SWITCH™ Toggle Sw itches](#) : [TL](#))

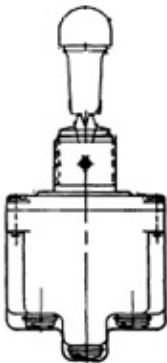


TL Series Toggle Switch, 4 pole, 2 position, Screw terminal, Locking Lever

Actual product
appearance may vary.

Product Specifications

Product Type	MICRO SWITCH™ Toggle Sw itch
Ampere/Voltage Range (Resistive Load)	0.5 A at 250 Vdc 0.75 A at 115 Vdc 0.5 A to 20 A at 0.5 Vdc to 28 Vdc 0.5 A to 15 A at 0.5 Vac to 277 Vac
Circuitry	4PST
Action	2 position

Circuitry/Operating action

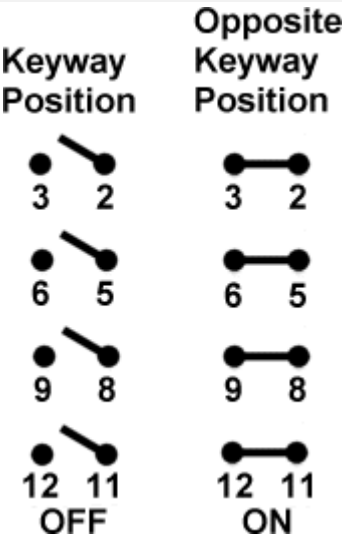

Mounting	Bushing 15/32 in
Termination	Screw
Lever Type	Locking

Lever Lock



Locked out
of center
position

Product Specifications

UL/CSA	L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"
Comment	Gold plated contacts, no spring clip
Availability	Global
UNSPSC Code	39122211
UNSPSC Commodity	39122211 Toggle Sw itch
Series Name	TL

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[4TL887-2D](#)