


4TL150-3D

([Home](#) : [Products](#) : [basics](#) : [Sw itches](#) : [MICRO SWITCH™ Toggle Sw itches](#) : [TL](#))

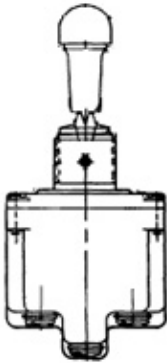


TL Series Toggle Switch, 4 pole, 2 position, Screw terminal, Locking Lever

Actual product
appearance may vary.

Product Specifications

Product Type	MICRO SWITCH™ Toggle Sw itch
Ampere/Voltage Range (Resistive Load)	0.5 A to 20 A at 0.5 Vdc to 28 Vdc 0.75 A at 115 Vdc 0.5 A at 250 Vdc 0.5 A to 15 A at 0.5 Vac to 277 Vac
Circuitry	4PDT
Action	2 position

Circuitry/Operating action

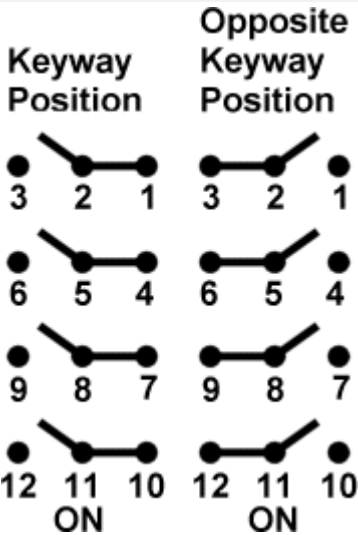

Mounting	Bushing 15/32 in
Termination	Screw
Lever Type	Locking

Lever Lock



Locked out
of center
position

Product Specifications

UL/CSA	L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"
Comment	Silver cadmium oxide contacts, w hite resilient cap on lever
Availability	Global
UNSPSC Code	39122211
UNSPSC Commodity	39122211 Toggle Sw itch
Series Name	TL

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[4TL150-3D](#)