

2TL887-3

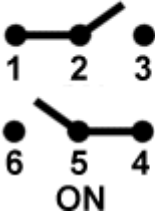
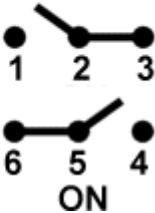
([Home](#) : [Products](#) : [basics](#) : [Sw itches](#) : [MICRO SWITCH™ Toggle Sw itches](#) : [TL](#))



TL Series Toggle Switch, 2 pole, 2 position, Screw terminal, Standard Lever

Actual product appearance may vary.

Product Specifications

Product Type	MICRO SWITCH™ Toggle Sw itch
Ampere/Voltage Range (Resistive Load)	0.5 A to 15 A at 0.5 Vac to 277 Vac 0.5 A to 20 A at 0.5 Vdc to 28 Vdc 0.5 A at 250 Vdc 0.75 A at 115 Vdc
Circuitry	DPDT
Action	2 position
Circuitry/Operating action	<div><div><div>Keyway Position</div><div></div></div><div><div>Opposite Keyway Position</div><div></div></div></div>
Mounting	Bushing 15/32 in
Termination	Screw
Lever Type	Standard
UL/CSA	L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"
Comment	Gold plated contacts, no spring clips, lubricated plungers, special cleaning operation, plunger for longer life
Availability	Global
UNSPSC Code	39122211
UNSPSC Commodity	39122211 Toggle Sw itch
Series Name	TL

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[2TL887-3](#)