


2TL1-6

( [Home](#) : [Products](#) : [basics](#) : [Sw itches](#) : [MICRO SWITCH™ Toggle Sw itches](#) : [TL](#) )

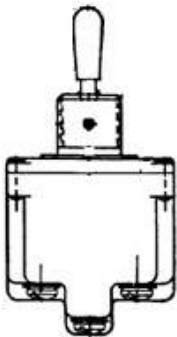

TL Series Toggle Switch, 2 pole, 2 position, Screw terminal, Standard Lever, Military Part Number MS24524-30

Actual product appearance may vary.

Product Specifications

Product Type	MICRO SWITCH™ Toggle Sw itch	
Ampere/Voltage Range (Resistive Load)	0.5 A to 10 A at 0.5 Vac to 277 Vac 0.5 A at 250 Vdc 0.75 A at 115 Vdc 0.5 A to 18 A at 0.5 Vdc to 28 Vdc	
Circuitry	DPST	
Action	2 position	
Circuitry/Operating action	<div><div><b>Keyway Momentary Position</b>  ON</div><div><b>Opposite Keyway Position</b>  OFF</div></div>	
Mounting	Bushing 15/32 in	
Termination	Screw	
MIL Spec. Number	MS24524-30	
Lever Type	Standard	
UL/CSA	L192: 10 A-125, 250, 277 Vac; 1/4 Hp-125 Vac; 1/2 Hp-250, 277 Vac; 3 A-125 Vac "L"	
Comment	Silver cadmium oxide contacts	
Availability	Global	
UNSPSC Code	39122211	
UNSPSC Commodity	39122211 Toggle Sw itch	
Series Name	TL	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[2TL1-6](#)