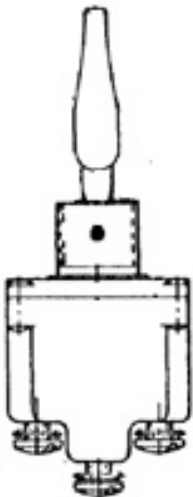


1TL119-7-A02

 

 
([Home](#) : [Products](#) : [basics](#) : [Sw itches](#) : [MICRO SWITCH™ Toggle Sw itches](#) : [TL](#))



TL Series Toggle Switch, 1 pole, 3 position, Screw terminal, Tab Lever

Actual product appearance may vary.

Product Specifications

Product Type	MICRO SWITCH™ Toggle Sw itch		
Ampere/Voltage Range (Resistive Load)	0.75 A at 115 Vdc 0.5 A to 10 A at 0.5 Vac to 7 Vac 0.5 A to 15 A at 0.5 Vdc to 28 Vdc 0.5 A at 250 Vdc		
Circuitry	SPDT		
Action	3 position		
Circuitry/Operating action	<div><div><div>Keyway</div><div>Momentary</div><div>Position</div><div></div></div><div><div>Center</div><div>Position</div><div></div></div><div><div>Opposite</div><div>Keyway</div><div>Momentary</div><div>Position</div><div></div></div></div>		
Mounting	Bushing 15/32 in		
Termination	Screw		
Lever Type	Tab		
UL/CSA	L 192: 10 A-125, 250, 277 Vac; 1/4 Hp-125 Vac; 1/2 Hp-250, 277 Vac; 3 A-125 Vac "L"		
Comment	Plastic lever		
Availability	Global		
UNSPSC Code	39122211		
UNSPSC Commodity	39122211 Toggle Sw itch		
Series Name	TL		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[1TL119-7-A02](#)