


1TL119-1-A02

 
([Home](#) : [Products](#) : [basics](#) : [Sw itches](#) : [MICRO SWITCH™ Toggle Sw itches](#) : [TL](#))

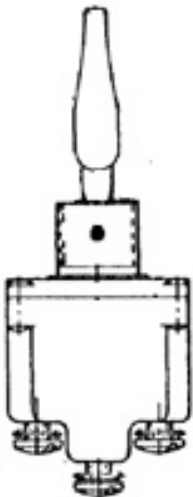

TL Series Toggle Switch, 1 pole, 3 position, Screw terminal, Tab Lever

Actual product appearance may vary.

Product Specifications

Product Type	MICRO SWITCH™ Toggle Sw itch
Ampere/Voltage Range (Resistive Load)	0.75 A at 115 Vdc 0.5 A to 20 A at 0.5 Vdc to 28 Vdc 0.5 A at 250 Vdc 0.5 A to 15 A at 0.5 Vac to 277 Vac
Circuitry	SPDT
Action	3 position
Circuitry/Operating action	<div><div><div>Keyway Position</div><div></div></div><div><div>Center Position</div><div></div></div><div><div>Opposite Keyway Position</div><div></div></div></div>
Mounting	Bushing 15/32 in
Termination	Screw
Lever Type	Tab
UL/CSA	L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"
Comment	Plastic lever
Availability	Global
UNSPSC Code	39122211
UNSPSC Commodity	39122211 Toggle Sw itch
Series Name	TL

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[1TL119-1-A02](#)