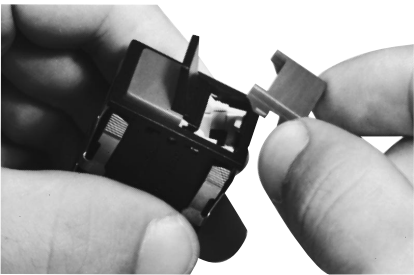


Manual Switches

Covers for Paddle Switches

AML53/55 Series



Colored covers simply snap into the top of paddle switch housings.

COLOR DISPLAY OPTIONS

Transmitted color — Color is displayed whether lamp is On or Off. Choice of 1-piece covers (types 10 or 20) or covers with clear cap and colored translucent insert (types 11 or 12).

Dead front hidden color/hidden legend — Cover appears black with lamp Off. Legend and color appear when illuminated (types 30 or 40).

Projected color — Translucent white cover with transparent colored insert (types 50 or 60). White cover appears colored when illuminated.

AML53 PADDLE SWITCH COVER ORDER GUIDE (All possible color combinations may not be available.)

For AML13, AML23, and AML33 incandescent or non-lighted display.

AML53-T	10	R	G
Paddle Switch Cover Type	Display/Legend Type	Cover Color	
 AML53-E 1/2 Cover	Transmitted Color 10 No legend 20 With legend on cap Transmitted Color (Clear cap and color insert) 11 No legend 21 With legend on insert Dead Front (Smoky gray cap and color insert) 30 No legend 40 With legend on insert ***Projected Color (White cap and color insert) 50 No legend 60 With legend on cap	1/2 cover, or one side of two-piece cover R Red Y Yellow G Green B Blue ***W White K* Black L* Gray A** Amber	Other side of two-piece cover (see note) R Red Y Yellow G Green B Blue ***W White K* Black L* Gray A** Amber

Note: Only one color code letter is necessary when ordering 1/2 covers.

Example: **AML53-T10RG**
Two-piece cover; with transmitted color, no legend; red and green.

*Not for lighted display.
**Not available with projected color.
***Insert is clear for projected color when "W" is used.

Manuals

AML55 PADDLE SWITCH COVER ORDER GUIDE (All possible color combinations may not be available.)

For AML35 neon display.

AML55-N	10	R	Y
Paddle Switch Cover Type	Display/Legend Type	Lens Color	Cover Color
 AML55-N Full Neon Cover, with colored lens	Transmitted Color 10 No Legend 20 With Legend	T Clear R Red	R Red Y Yellow G Green B Blue W White K Black L Gray

AML55-N covers have a colored lenticular lens window which extends over the neon lamp.

Example: **AML55-N10RY**
Full neon paddle switch cover; with transmitted color, no legend; red lens and yellow cover.

 
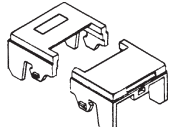
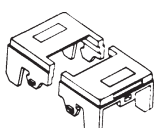
Manual Switches

Covers for Paddle Switches

AML55 Series

AML55 PADDLE SWITCH COVER ORDER GUIDE (All possible color combinations may not be available.)

For AML15 and AML25 LED display.

AML55-T	10	Y	R
		See notes below	
Paddle Switch Cover Type	Display/Legend Type	Cover Color – See notes below	
AML55-E  1/2 Cover (For one LED)*	Transmitted Color 10 No Legend 20 With Legend	1/2-cover, or LED side of two-piece covers*	Other side of two piece covers
AML55-T  Two-Piece Cover (For one LED)		R Red Y Yellow G Green B Blue W White K Black L Gray	R Red Y Yellow G Green B Blue W White K Black L Gray
AML55-H  Two-Piece Cover (For two LED's)			

AML55-E, -T, and -H covers have an open window which allows LED's to be flush with the cover surface.

* Notes:
¹ Only one color code letter is necessary for AML55-E 1/2 covers.
² To order a 1/2-cover without the LED "window," specify an AML53-E listing from the previous page.

Example: **AML55-T10YR**
Two-piece cover; with LED window in one side, transmitted color, no legend; yellow (LED side) and red (non-LED side).

HOW TO ORDER LEGENDS FOR PADDLE SWITCH COVERS
When specifying legended paddle switch covers, submit a legend order sheet to cover each catalog listing. These forms identify the maximum number of lines per area and the maximum characters per line, based on the type size you request.

To insure proper legend orientation, paddle switch housings (when viewed from the panel front) should have the "MICRO SWITCH" identification facing UP or to the LEFT.

Legend order sheets for covers are shown on the following pages. Reproduce them on your office copier or request a pad of them from the 800 number.:
Legend Sheet
AML53 Covers
AML55 Covers
Form No.
FO-63567
FO-63565

Account NO 126 - 284

Catalog Listing
AML53 —

Customer P.O. No.	Customer Dwg. No.
MICRO SWITCH Sales Order	Schedule No.

Customer: _____

Address: _____

(city) _____ (state) _____

Instructions

1. Fill in appropriate catalog listing - one listing/sheet.
2. Check proper figure #, Type size, Type color.
3. Fill in quantity required.
4. Indicate legends desired — Do not exceed maximums shown in legend order guide.

Note

1. For Proper Legend Orientation, AML housings (when viewed from front of panel) should have "MICRO SWITCH" logo oriented "UP" on square devices and "UP" or to the "LEFT" on rectangular devices.
2. Please use black ink in filling out this form to help us process your order.

LEGEND ORDER GUIDE											
Button: Type Orientation		Figure No		Max Lines/Area				Max Characters/Line			
		5/64	7/64	9/64	13/64	5/16		5/64	7/64	9/64	13/64
AREA 1	E	1	2	2	1	1	0	7	5	5	3
		1	2	1	1	1	0	5	4	4	2
AREA 1	E	2	2	2	1	1	0	7	5	5	3
		1	2	1	1	1	0	5	4	4	2
AREA 2	T	3	2	2	2	1	1	7	5	5	3
		1	2	1	1	1	0	5	4	4	2

Standard Legend Placement — 1. Transmitted Color—Legend on outer shell (Button Use Special Legends Section for other placements.

2. Dead Front—Legend on insert

3. Projected Color - Legend on outer shell (Button)

4. Transmitted color with color with clear cap legend on insert.

5. All legends will be centered within the legendable areas

LEGEND ORDER CHART

Customer Part No	Fig No	Type Size				Ink Color		But-ton Qty		Area 1		Area 2	
		5/64	7/64	9/64	13/64	5/16	Black	White		Sequence: Left-to-Right or Top-to-Bottom	1st Line	2nd Line	

FO-65567-F _____ (Signature) _____ (Date)

A3

Modified Gothic

Modified Gothic lettering (A thru Z), numerals (0 thru 9) and Symbols below available in 5/64, 7/64, 9/64, 13/64 and 5/16.

.	:	;	!	?	'	—	"	/	(	)	*	&
\$	¢	#	%	o	+	-	±	÷	x	=	≠	<
→	↖	↗	↘	↙	↘	↗	↖	↘	↗	↖	↘	↗

STANDARD SYMBOLS AVAILABLE

SPECIAL LEGENDS

NOTE: Use this area to show special Legend Locations or Configurations NOT shown above. NON-STANDARD legends will involve additional charges and increased delivery time.

Fig. "A"

Fig. "B"

AML Paddle (Cover) Legend Sheet For LED and Neon Style/Product Specification

Page ___ of ___

Account NO 126-284

Catalog Listing AML55 —		
Customer P.O. No.	Customer Dwg. No.	Schedule No.
MICRO SWITCH Sales Order		Line Number

Customer:

Address:

city)

[**state**)

Instructions

1. Fill in appropriate catalog listing - one listing/sheet.
2. Check proper figure #, Type size, Type color.
3. Fill in quantity required.
4. Indicate legends desired — Do not exceed maximum

Note

1. For Proper Legend Orientation, AML housings (when viewed from front of panel) should have "MICRO SWITCH" logo oriented "UP" on square devices and "UP" or to the "LEFT" on rectangular devices.
2. Please use black ink in filling out this form to help us process your order.

SPECIAL LEGENDS NOTE: Use this area to show special Legend Locations or Configurations NOT shown below; NON-STANDARD legends will involve additional charges and increased delivery time.	Fig. "A" Fig. "B"
--	---------------------------------

Modified Gothic lettering (A thru Z), numerals (0 thru 9) and Symbols below available in 5/64, 7/64, 9/64, 13/64 and 5/16.	A3 Modified Gothic											
STANDARD SYMBOLS AVAILABLE												
·	,	:	;	!	?	'	"	/	(	)	*	&
\$	¢	#	%	o	+	-	±	÷	x	=	≠	>
→	↑	↓	←	CR	1/4	1/2	3/4	1/3	2/3	@	∞	

[illegible]

Standard Legend Placement – Use Special Legends Section for other placements.

1. All Legends will be centered within the legendable areas

LEGEND ORDER CHART

[illegible]

FO-63565-C

(Signature)

(Date)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Honeywell:

[AML53-E103](#) [AML53-E10A](#) [AML53-E10B](#) [AML53-E10G](#) [AML53-E10K](#) [AML53-E10L](#) [AML53-E10R](#) [AML53-E10W](#)
[AML53-E10Y](#) [AML53-E11B](#) [AML53-E11G](#) [AML53-E11R](#) [AML53-E11W](#) [AML53-E11Y](#) [AML53-E200](#) [AML53-E20B](#)
[AML53-E20G](#) [AML53-E20K](#) [AML53-E20R](#) [AML53-E20W](#) [AML53-E20Y](#) [AML53-E300R](#) [AML53-E30R](#) [AML53-E40R](#)
[AML53-E50R](#) [AML53-E50W](#) [AML53-E60R](#) [AML53-T10AA](#) [AML53-T10BB](#) [AML53-T10BG](#) [AML53-T10GG](#) [AML53-](#)
[T10GK](#) [AML53-T10GR](#) [AML53-T10KK](#) [AML53-T10KL](#) [AML53-T10LK](#) [AML53-T10LL](#) [AML53-T10RG](#) [AML53-T10RK](#)
[AML53-T10RR](#) [AML53-T10RY](#) [AML53-T10WG](#) [AML53-T10WW](#) [AML53-T10WY](#) [AML53-T10YK](#) [AML53-T10YW](#)
[AML53-T11KK](#) [AML53-T11YY](#) [AML53-T20BB](#) [AML53-T20GG](#) [AML53-T20GK](#) [AML53-T20KK](#) [AML53-T20RG](#)
[AML53-T20RR](#) [AML53-T20WW](#) [AML53-T20WY](#) [AML53-T20YW](#) [AML53-T20YY](#) [AML53-T21GR](#) [AML53-T30BB](#)
[AML53-T30GG](#) [AML53-T30KK](#) [AML53-T30LL](#) [AML53-T30RR](#) [AML53-T30WW](#) [AML53-T40RR](#) [AML53-T50GG](#)
[AML53-T50RG](#) [AML53-T60BB](#) [AML53-T60GG](#) [AML53-T60RR](#) [AML53-T60YY](#) [AML53-T10YY](#) [AML55-E10B](#) [AML55-](#)
[E10C](#) [AML55-E10G](#) [AML55-E10K](#) [AML55-E10L](#) [AML55-E10R](#) [AML55-E10Y](#) [AML55-H10AA](#) [AML55-H10BB](#)
[AML55-H10GG](#) [AML55-H10GR](#) [AML55-H10GY](#) [AML55-H10KK](#) [AML55-H10LL](#) [AML55-H10RG](#) [AML55-H10RK](#)
[AML55-H10RR](#) [AML55-H10RY](#) [AML55-H10WW](#) [AML55-H10YG](#) [AML55-H10YY](#) [AML55-H20GR](#) [AML55-H20KK](#)
[AML55-H20WW](#) [AML55-N10RB](#) [AML55-N10RG](#) [AML55-N10RK](#)