


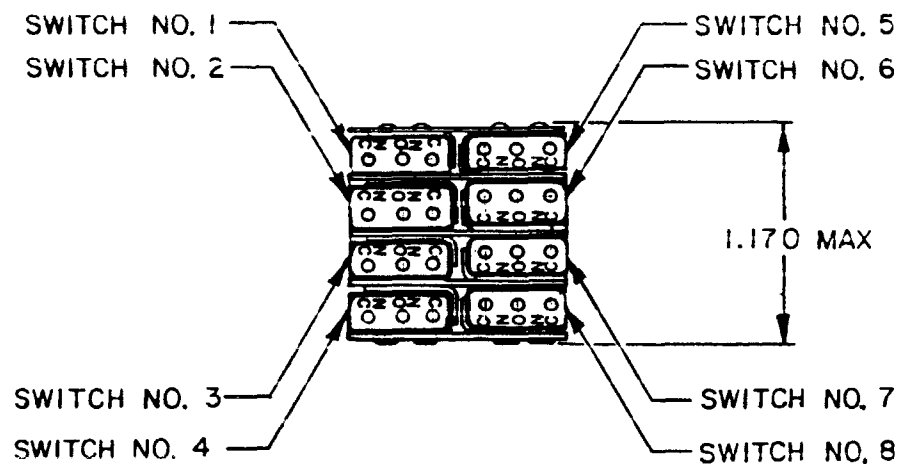


 



 
 
 
 


FED. MFG. CODE 91020

CHART 2



<p>"A"</p>  <p>LOCKED IN THREE POSITIONS</p>	<p>"B"</p>  <p>LOCKED IN CENTER AND EXTREME POSITION (KEYWAY SIDE)</p>	<p>"D"</p>  <p>LOCKED OUT OF CENTER POSITION</p>	<p>"E"</p>  <p>LOCKED IN CENTER POSITION</p>
<p>"F"</p>  <p>LOCKED IN EXTREME POSITION (OPPOSITE KEYWAY)</p>	<p>"G"</p>  <p>LOCKED IN EXTREME POSITION (KEYWAY SIDE)</p>	<p>"H"</p>  <p>LOCKED OUT OF CENTER AND EXTREME POSITION (KEYWAY SIDE)</p>	<p>"J"</p>  <p>LOCKED OUT OF CENTER AND EXTREME POSITION (OPPOSITE KEYWAY)</p>
<p>"K"</p>  <p>LOCKED IN CENTER AND EXTREME POSITION (OPPOSITE KEYWAY)</p>	<p>"L"</p>  <p>LOCKED OUT OF EXTREME POSITION (KEYWAY SIDE)</p>	<p>"M"</p>  <p>LOCKED OUT OF AND INTO EXTREME POSITION (OPPOSITE KEYWAY)</p>	<p>"N"</p>  <p>LOCKED OUT OF EXTREME POSITION (OPPOSITE KEYWAY)</p>
			<p>"P"</p>  <p>LOCKED OUT OF AND INTO EXTREME POSITION (KEYWAY SIDE)</p>

- 1 - UNIT INCLUDES "23SX" TYPE (GOLD CONTACT) BASIC SWITCH (8)
(MEETS REQUIREMENTS OF MIL-PRF-8805/4)
- 2 - SWITCHES DO NOT NECESSARILY OPERATE SIMULTANEOUSLY
- 3 - PLATED TERMINALS WILL ACCEPT "AMP INC." .058 DIA PIN RECEPTACLES
- 4 - SWITCH NUMBERS MARKED ON END OF BASIC SWITCHES
- 5 - TERMINAL DESIGNATION MARKED ON BOTH SIDES OF UNIT
- 6 - DULL FINISH ON LEVER AND BUSHING
- 7 - FLAT WHITE RESILIENT SILICONE (50 DUROMETER APPROX)
- 8 - SUFFIX LETTER MUST BE ADDED FOR DESIRED TYPE TOGGLE LOCKING
(SEE CHART FOR RECOMMENDED LOCKING COMBINATIONS)
- 9 - FOR REPLACEMENT BUTTON SEE MICRO SWITCH CATALOG LISTING
15PA90-6W
- 10 - HARDWARE FURNISHED ASSEMBLED WITH SWITCH OR IN PACKET
15PA313-AT PER MIL-PRF-8805
- 11 - REPLACEMENT MOUNTING HARDWARE PACKET 15PA313-AT

WEIGHT 11 LB APPROX

F

LA

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Honeywell:](#)

[68AT34-1A](#)