

## AMS-9 MICRO-MINI SURFACE MOUNT CONTACT




- UL and ULC listed
- ROHS compliant
- ½" operating gap
- Alnico 5 magnet
- Available in ivory, gray, and brown

### Application

The AMS-9 Micro-Mini Surface Door Contact is a UL listed, ROHS compliant, magnetic contact designed to provide reliability in the tightest spaces. The AMS-9 is perfect for any application where space is limited.

### Dimensions

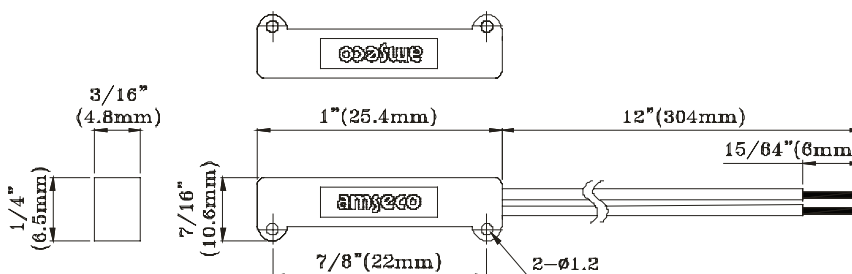

### Specifications

Model	Color	Stock Number	Contact	Contact Rating	Contact Type	Max. Carry Current	Max. Switching Current	Breakdown Voltage	Operating Gap	Mounting Method	Operating Temperature Range
AMS-9	Ivory	4350222	22AWG 12" Lead	10VA	Form A N.O	1.5 Amp	.5 Amp	350VDC	½"	Self-adhesive	32°F to 120°F (0°C to 49°C)
	Brown	4350090									
	Gray	4350091									

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AMSECO:](#)

[505-90G](#) [505-90B](#) [505-90I](#) [AMS-9-B](#) [AMS-9-G](#) [AMS-9-I](#)