


► DE-100 DOUBLE-ENDED SERIES

0.100 (2.54) Centers

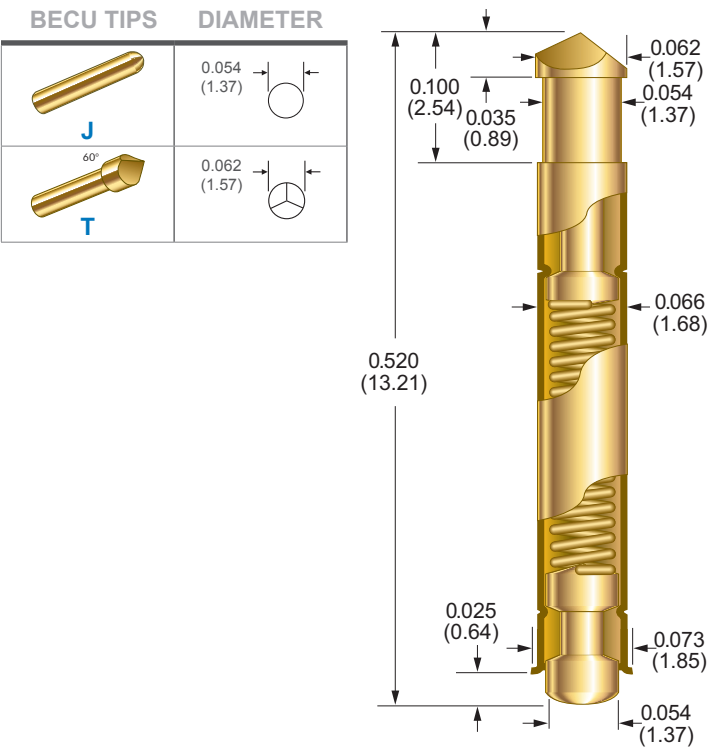

PROBE SPECIFICATIONS

Minimum Centers	0.100 (2.54)
Drill Size	1.75 mm – 0.067/0.069 (1.70/1.75)
Current Rating	3 A continuous
Spring Force	3.00 oz (85 g) @ 0.050 (1.27) travel
Typical Resistance	< 50 mΩ
Maximum Travel	0.080 (2.03)
Working Travel	0.050 (1.27)

MATERIALS

Barrel	Nickel/silver, gold plated
Spring	Music wire, gold plated
Plunger	Beryllium copper, gold plated

HOW TO ORDER

DE - 100 - J - 3 - G	
	1 2 3 4 5
1 ► SERIES	DE
2 ► SIZE	100
3 ► TIP STYLE	J, T
4 ► SPRING FORCE	3 oz.
5 ► PLUNGER PLATING	G GOLD

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Smiths Interconnect:](#)

[DE-100-T-3-G](#)