 



► DE-50 DOUBLE-ENDED SERIES

0.050 (1.27) Centers

BECU TIPS	DIAMETER
 D	0.033 (0.84) 
 T45	0.033 (0.84) 
 T60	0.033 (0.84) 
 U	0.026 (0.66) 

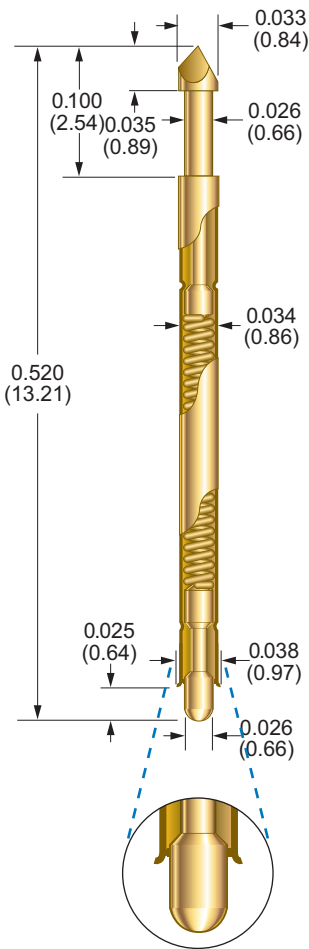

PROBE SPECIFICATIONS

Minimum Centers	0.050 (1.27)
Drill Size	#64 – 0.035/0.0365 (0.89/0.93)
Current Rating	3 A continuous
Spring Force	2.00 oz (57 g) @ 0.050 (1.27) travel
Typical Resistance	< 50 mΩ
Maximum Travel	0.080 (2.03)
Working Travel	0.050 (1.27)

MATERIALS

Barrel	Nickel/silver, gold plated
Spring	Music wire, gold plated
Plunger	Beryllium copper, gold plated

HOW TO ORDER

DE - 50 - D - 2 - G	
	1 2 3 4 5
1 ► SERIES	DE
2 ► SIZE	50
3 ► TIP STYLE	D, T45, T60, U
4 ► SPRING FORCE	2 oz.
5 ► PLUNGER PLATING	G GOLD

1. Bottom plunger travels to “below flush” to the barrel end.
Dimensions are in inches (mm) | All specifications are subject to change

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Smiths Interconnect:](#)

[100158-006](#)