

Double Row Angle Adjust Tube Lighting from Inspired LED




Mounting Options to Meet Every Need:



- Direct your light where it's most needed.
- Snap-in mounts allow for simple grab and twist adjustment.
- Double the light of the Single Row Angle Adjust Tubes.
- Powered by 12VDC source from Inspired LED:
 - Plug-in Power Supply
 - Hard-wire Dimmable Transformer
- Available in Warm White (3000K) or Cool White (6000K).
- Each LED outputs roughly 6.5 lumens with a 120° viewing angle.
 - Rated for 100,000 hours of use.
 - No IR or UV light – safe for lighting delicate materials.
- Available in standard sizes:
 - 2 Foot Length (114 LEDs)
 - 3 Foot Length (174 LEDs)
 - 4 Foot Length (234 LEDs)
- Available in custom lengths – call for information.
- Manufactured in Tempe, Arizona.

Power Source	Maximum Lighted Length
1 Amp (12 Watt)	27"
1 Amp Mini (12 Watt)	27"
1.5 Amp Skinny (18 Watt)	40"
2 Amp (24 Watt)	54.5"
40 Watt Dimmable Transformer	90.5"
3.8 Amp (45.6 Watt)	102.5"
60 Watt Dimmable Transformer	134.5"
100 Watt Dimmable Transformer	224"

12V DC Power Supply

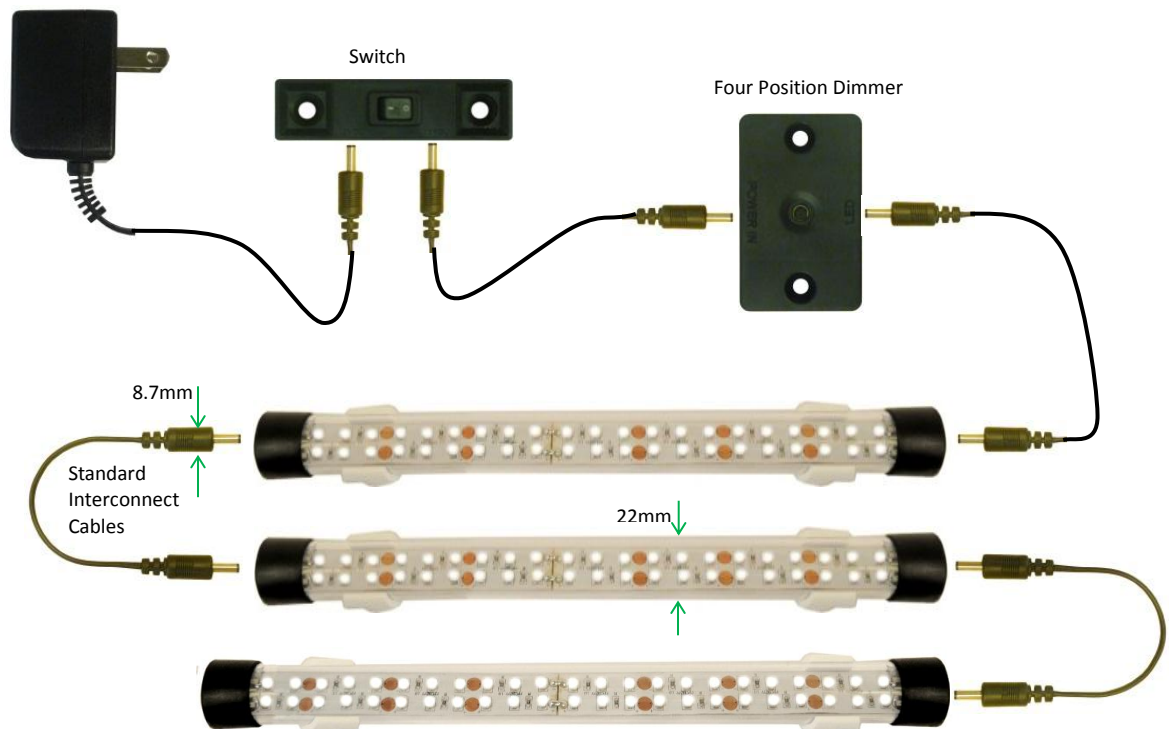

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Inspired LED:

4947 4947-M