


inspired LED *Infinity 2-Prong Screw Terminal*

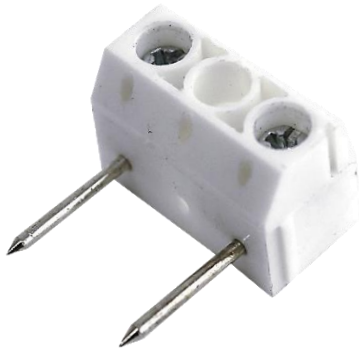

SKU #3571

Product Features:


Dual prongs extend from low-profile white plastic body, housing two Philips-head screw terminals

Specifications:

Dimensions- 0.69" x 0.40" x 0.61"

Net Weight- 2 grams

Max Load- 6 AMPS

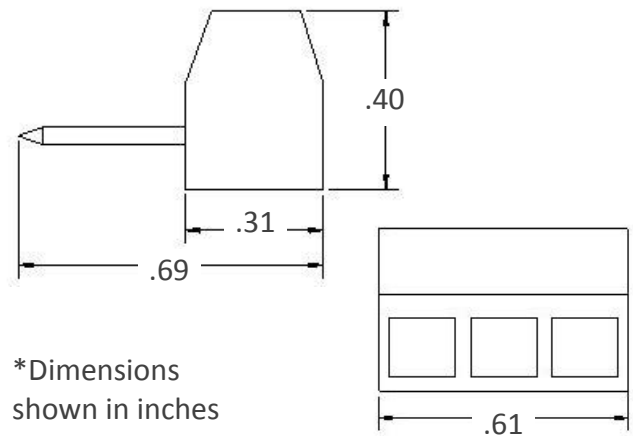


Instructions: To install, you will need Infinity flex, 2-prong screw terminals, solid 2-conductor outdoor-rated cable, wire strippers, outdoor-rated silicone, heat shrink (if desired)



1. Measure Infinity Series Dura-flex and cut to length according to instructions, taking note of polarity marked along the strip.



2. Align 2-prong screw terminal to small holes on sides of Infinity Dura-flex, and insert so that barbs pierce the copper wiring running along both sides.

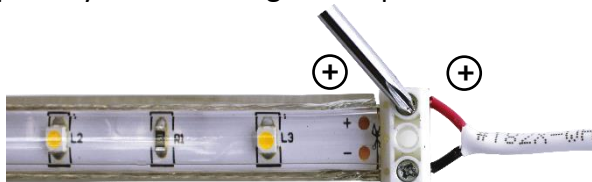

3. Open screw terminals, strip & insert wire (matching polarity of strip), then tighten screws back down. Repeat steps 2-3 to connect to next strips in series.



4. Use cable from first flex strip in series to wire nut back to power source. Reinforce connections with silicone or heat shrink.



inspiredled.com



orders@inspiredled.com



(480) 941-4286

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Inspired LED:

3571