

## DOUBLE POLE LINE VOLTAGE SELECTOR SWITCHES

This rugged fully enclosed housing is built for tough applications. The positive detect action, status indication and variety of contact configurations make this series ideal for a variety of needs.

### APPLICATIONS

- Consumer power supplies
- Lower cost dual use power supplies

### KEY FEATURES:

- Status indication: variety of markings available
- Variety of terminal styles
- Electrical life: 10,000 cycles
- UL recognized and CSA certified and VDE approved
- Variety of mounting styles
- Silver plated contacts

# Series SE1022



ACTUAL SIZE

### ORDERING INFORMATION:

| Part Number        | Terminals          | Dimensions                      | Marking   |
|--------------------|--------------------|---------------------------------|-----------|
| <b>18-000-0016</b> | .110 quick connect | 1.615 L x .650 W x .625 H       | 230V/115V |
| <b>18-000-0019</b> | Right angle        | 1.030 L x .650 W x .625 H       | 230V/115V |
| <b>18-000-0022</b> | PC                 | 1.030 L x .650 W x .625 H       | 230V/115V |
| <b>18-000-0040</b> | .110 quick connect | Snap in: .677 x 1.240 Cut out * | 230V/115V |

\* It is recommended that panel thickness range from .015 to .125" (.038 to 3.18 mm) with switch cut-out punched from front of panel.

### STANDARDS / AGENCY / RATINGS:



## MECHANICAL / ELECTRICAL CHARACTERISTICS:

### Circuit:

DPDT (Form CC)

### Electrical life:

10,000 cycles

### Housing/actuator:

Nylon 94 V0

### Terminal base:

phenolic laminate

### Terminals:


silver plated copper

### Electrical ratings:


| Circuitry | Current | Voltage     |
|-----------|---------|-------------|
| DPDT*     | 10 Amp  | 125 VAC     |
| DPDT*     | 5 Amp   | 250 VAC     |
| DPDT**    | 10 Amp  | 125 VAC-T85 |
| DPDT**    | 5 Amp   | 250 VAC-T85 |

\* UL and CSA recognized  
\*\* VDC recognized


## 18-000-0016

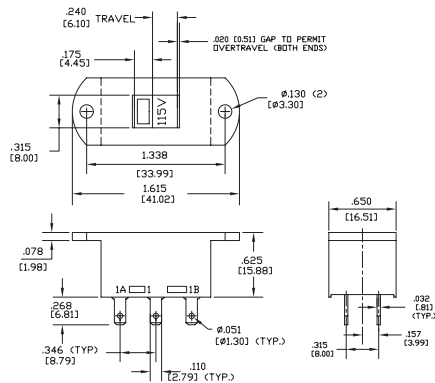


## 18-000-0019

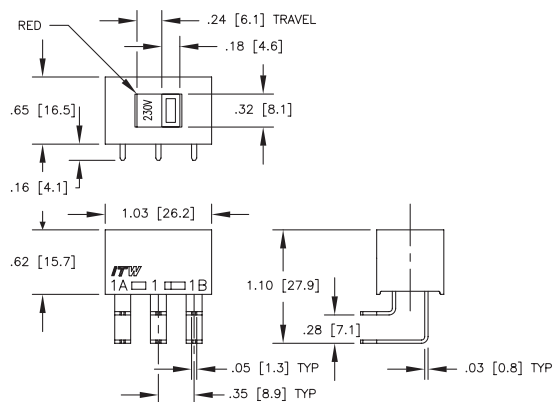

## 18-000-0022

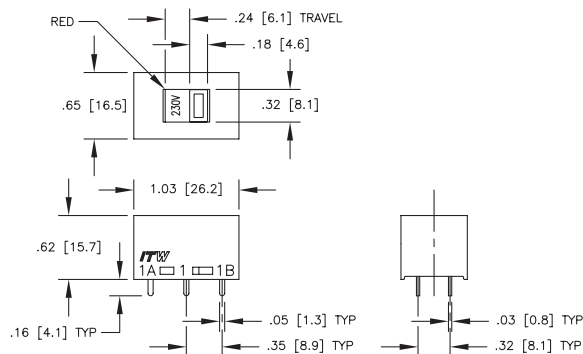

## 18-000-0040

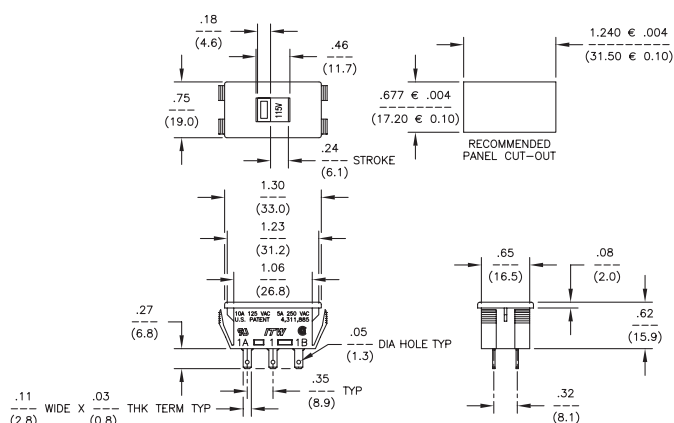

Designs and specifications are subject to change without notice due to product improvement.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

ITW Switches:

[18-000-0019](#) [18-000-0022](#) [18-000-0040](#)