

SUB-MINIATURE T-05 SPACE SAVER

This sub-miniature pushbutton switch offers high quality and reliability in a very small package. With gold contacts, this switch offers up to 1,000,000 cycles. This switch is ideal for applications where PC board space is at a premium.

APPLICATIONS

- Reset switch
- Detect switch

KEY FEATURES:

- Momentary action
- Gold contacts
- PC terminals
- SPST-NO (Form A) circuitry
- Variety of actuator lengths
- Up to 1,000,000 mechanical actuations

ORDERING INFORMATION:

Part Number	Button Height
034-550-001	0.06
034-550-002	0.50
034-550-005	0.15
034-550-006	0.25
034-550-010	0.37
034-550-015	0.19



ACTUAL SIZE

STANDARDS / AGENCY / RATINGS:



MECHANICAL / ELECTRICAL CHARACTERISTICS:

Circuit:

SPST-NO (Form A) Momentary

Temperature rating:

-30°C to +65°C
(-22°F to +149°F)

Life (mechanical):

1,000,000 actuations

Contact rating:

100 mA @ 125 VAC

Actuator:

thermoplastic (PBTP)


Can:

Nickel-silver


Contacts & terminals:

gold over nickel plate


034-550-001

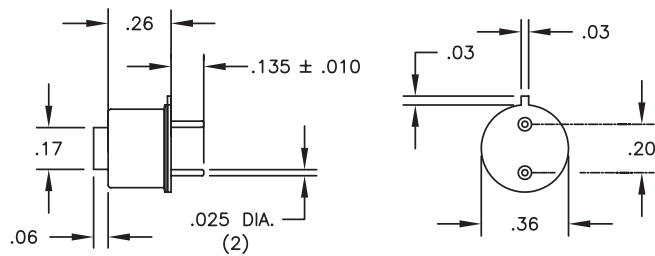


034-550-002

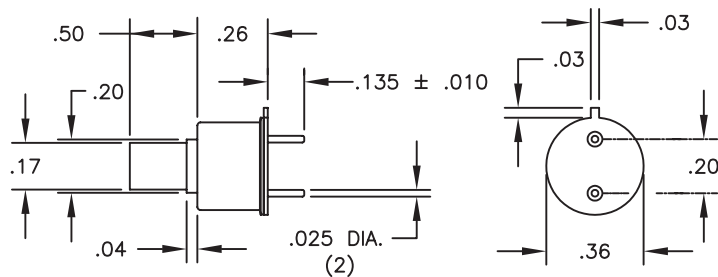


034-550-005

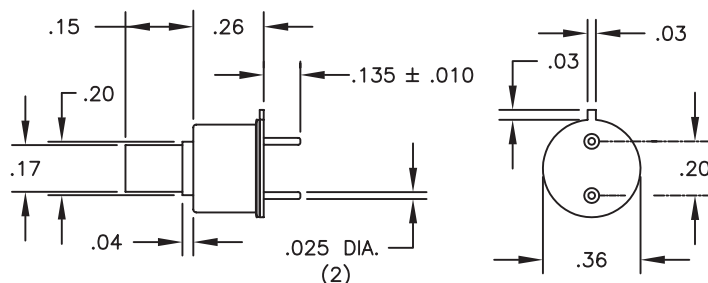


034-550-006

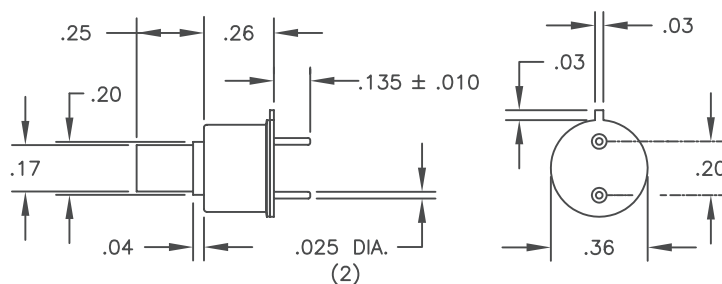

034-550-015

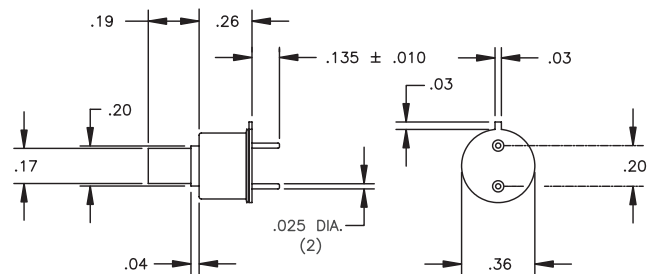

034-550-010

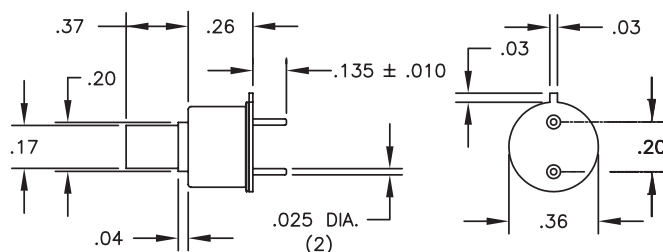

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ITW Switches:](#)

[034-550-001](#)