


FEATURES

Non-Polarized
24 Volt DC Operation
12V AC or DC Operation
CRI ≥ 80 (WW)
 ≥ 70 (CW)

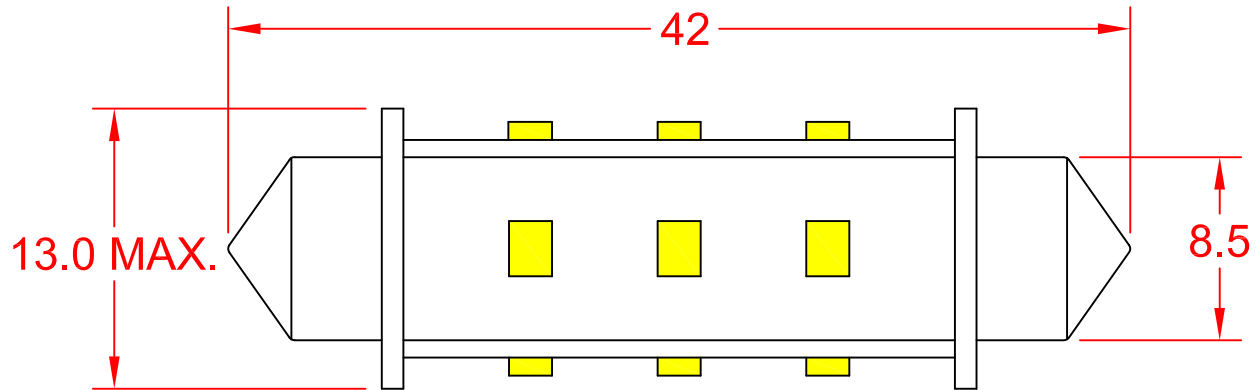

 
SPECIFICATIONS

PARAMETERS	SYMBOL	VALUES			UNIT
		MIN	TYP	MAX	
Input Voltage	Vin	10	12	30	VDC
Input Current	Iin	0.02	0.05	0.07	A
Power Consumption	P		0.6		W
CRI	Ra	≥ 80 (Warm White) / ≥ 70 (Cool White)			
CCT	- -	3000 (Warm White) / 6000 (Cool White)			K
Luminous Intensity	Φ	50-60 (Warm White) 40-50 (Cool White)			Lm
Operating Temperature	Topr	-20	25	40	°C

ACCESSORIES

SOCKET: 2910F-47

JKL PART NUMBERS: LE-3042-02-CW and LE-3042-02-WW

			METRIC  THIRD ANGLE PROJECTION		DIMENSIONS ARE IN MILLIMETERS TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- REF. 2 PL +/- REF. ANGLE +/-		JKL COMPONENTS CORPORATION TITLE NON-POLARIZED 360 DEGREES LED FESTOON LAMP					
B	SPECIFICATIONS CHANGES	6/2/14	DRAWN BY		APPV'D BY	DATE	SIZE	FSCM NO.	DRAWING NO.			
A	ADD FEATURES/ACCESS, CHNG SPEC	11/4/13	L. WENGSTROM		S.C.	6/2/14	A	55335	LE-3042-02 MULTI			
	RELEASED	10/8/13					SCALE		RELEASED DATE	REVISION DATE	REV. NO.	SHEET
REV. NO.	DESCRIPTION/ECO NUMBER	APPV'D DATE	- CAD DRAWING - MANUAL REVISIONS NOT PERMITTED				NONE		10/8/13	6/2/14	B	1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JKL Components:](#)

[LE-3042-02WW](#) [LE-3042-02CW](#)