


FEATURES

T-3 1/4 WEDGE BASE - NON-POLARIZED
 WIDE INPUT VOLTAGE RANGE
 LOW POWER USAGE
 OMNI DIRECTIONAL LIGHT DISTRIBUTION
 EFFICACY OF 83 Lm/WATT
 CRI >80
 COLOR TEMPERATURE 3000°K

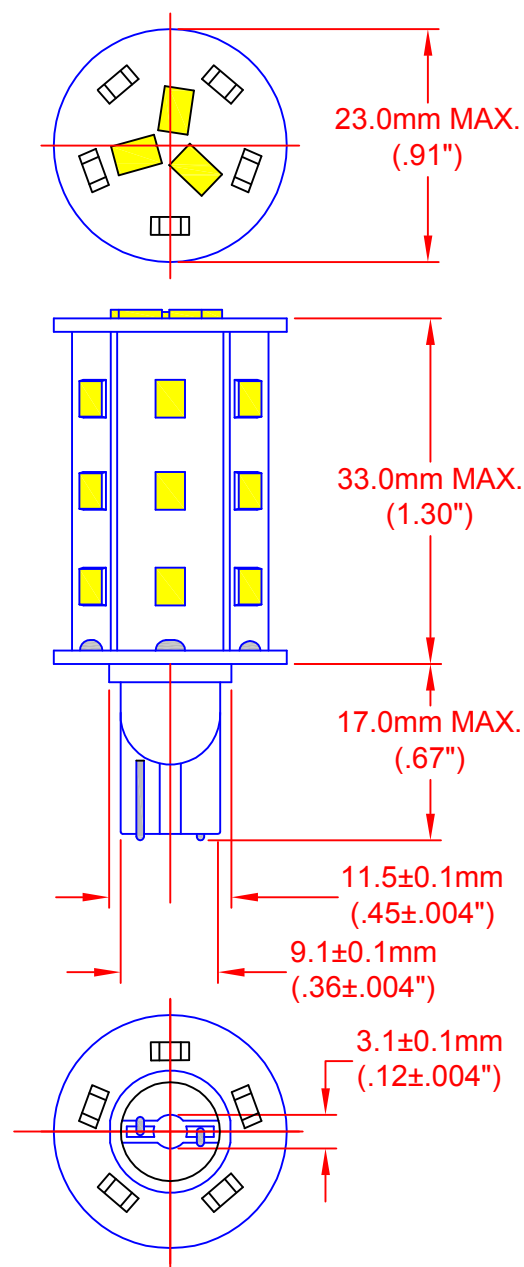

JKL PART NUMBER	VOLTAGE AC/DC			WATTS			ILLUMINANCE FLUX lm TYP
	MIN	NOM	MAX	MIN	NOM	MAX	
LE-WB18-12WW	10	12	30	2.0	2.4	2.6	200

JKL PART NUMBER: LE-WB18-12WW

METRIC			DIMENSIONS ARE IN MILLIMETERS			JKL COMPONENTS CORPORATION			
THIRD ANGLE PROJECTION			TOLERANCE UNLESS OTHERWISE SPECIFIED			TITLE			
			1 PL +/- 0.2			T-3 1/4 WEDGE BASE MULTI CHIP LED LAMP			
			2 PL +/- 0.20						
			ANGLE +/-						
DRAWN BY			APPV'D BY			DATE			
L. WENGSTROM			L.R.			2/6/16			
- CAD DRAWING -			SCALE			NONE			
MANUAL REVISIONS NOT PERMITTED			FSCM NO.			55335			
REV. NO.			RELEASED DATE			11/8/15			
DESCRIPTION/ECO NUMBER			APPV'D DATE			2/6/16			
REV. NO.			REV. NO.			A			
SHEET			SHEET			1 OF 1			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JKL Components:](#)

[LE-WB18-12WW](#)