


Features

VOLTAGE: 12V DC
CURRENT: 5.0 Amps

STANDARD PACKAGING:
5 METER REEL (300 LED'S)

12V COOL WHITE LED BENDABLE FLEX RIBBON

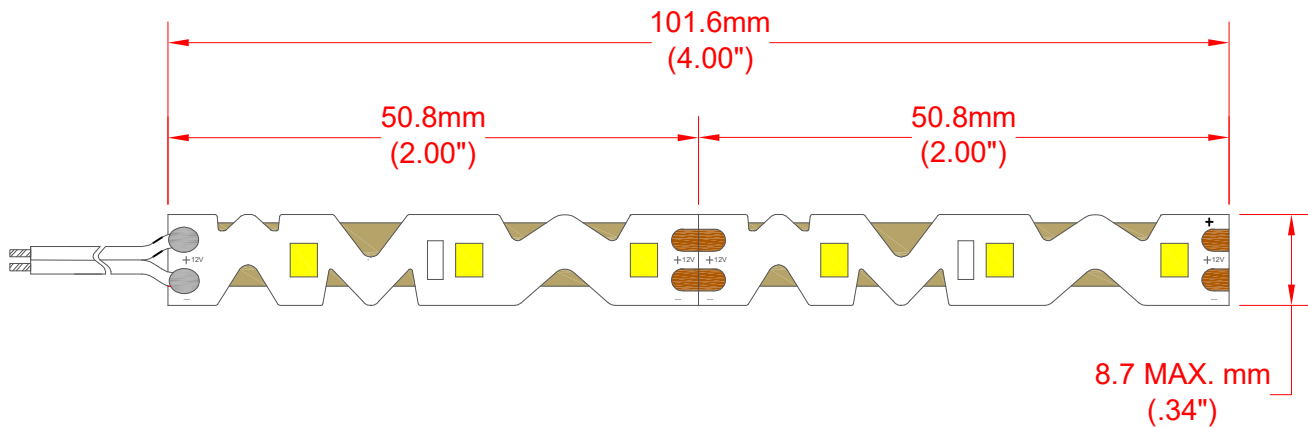

JKL Part Number	Color	Number of LED's	Input Voltage (V DC)	Power (W)	Radiance Angle	CCT (K)	Lumen Flux (lm)
ZFS-8500BND-CW	Cool White	300	12	60	120°	6000°K	4760



ATTENTION

OBSERVE PRECAUTION
FOR HANDLING ELECTROSTATIC
DISCHARGE SENSITIVE DEVICES

			METRIC		DIMENSIONS ARE IN mm (INCHES)		JKL COMPONENTS CORPORATION			
			THIRD ANGLE PROJECTION		TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- REF. 2 PL +/- REF. ANGLE +/-		TITLE 12V COOL WHITE LED BENDABLE FLEX RIBBON			
			DRAWN BY L. WENGSTROM		APPV'D BY L.R.		DATE 2/15/17	SIZE A	FSCM NO. 55335	DRAWING NO. ZFS-8500BND-CW
RELEASED & CANCEL PL-1603-04			2/15/17		- CAD DRAWING - MANUAL REVISIONS NOT PERMITTED		SCALE NONE		RELEASED DATE 2/15/17	REVISION DATE
REV. NO.	DESCRIPTION/ECO NUMBER		APPV'D DATE						REV. NO.	SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JKL Components:](#)

[ZFS-8500BND-CW](#)