

165° WIDE BEAM LED CHANNEL for MEDIUM or LARGE SIGN BOXES

FEATURES

12V DC

IP67


50,000 Life Hours/5 Year Warranty

108 lm/W High Efficacy

Operating Temperature -20°C to +50°C

165° Wide Beam

30 Modules Per Strand

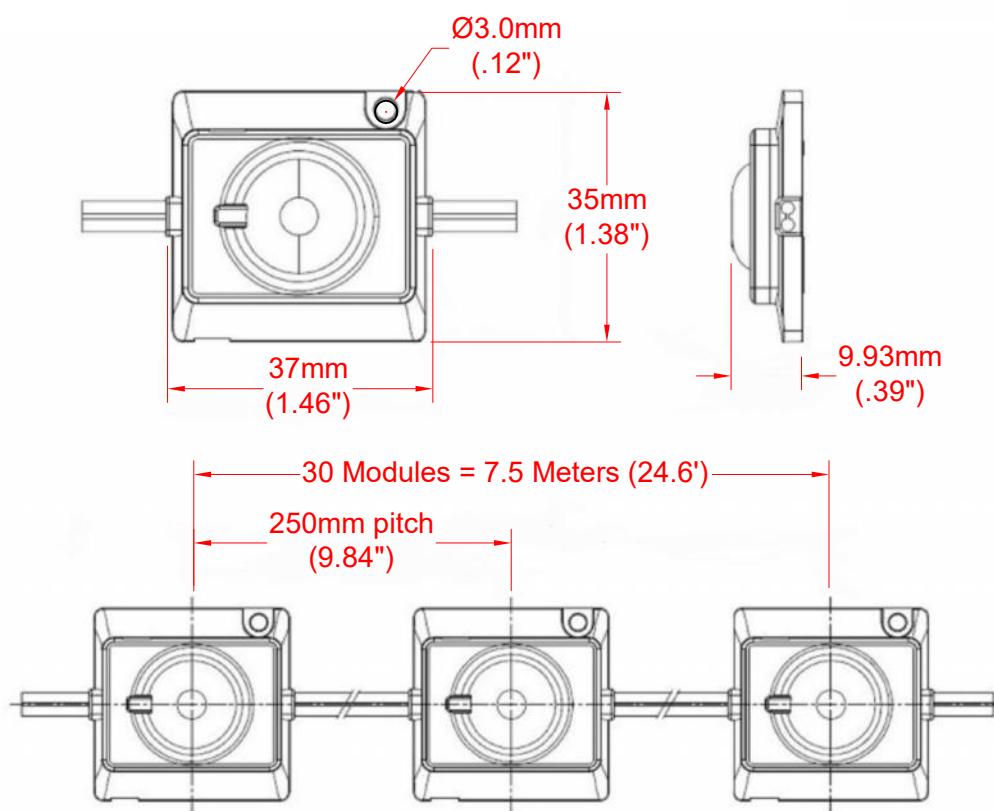

NOTES:

1. Mounting can be accomplished with double sided tape that is on the backside of modules. Screw holes are also present.
2. Wire with Red Stripe is Positive Input.
3. Use no more than 30 modules in series.
4. Take care to prevent exposed wire on the ends.



JKL Part Number	Input Voltage	Power per Module	CCT	Beam Angle	CRI	Lumen Flux Per Module	Lumen Efficacy	No. Modules Per a Pack
ZM-180-CW	12V DC	1.3 W	6500K	165°	Ra80	140 lm	108 lm/W	30/7.5 Meters

		METRIC THIRD ANGLE PROJECTION	DIMENSIONS ARE IN mm (INCHES)		JKL COMPONENTS CORPORATION		
			TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- REF. 2 PL +/- REF. ANGLE +/-				
DRAWN BY L. WENGSTROM		APPVD BY S.C.	DATE 9/14/19	TITLE WIDE BEAM LED CHANNEL MODULE			
RELEASED 9/14/19		APPVD DATE 9/14/19	SIZE A	FSCM NO. 55335	DRAWING NO. ZM-180-CW		
REV. NO.	DESCRIPTION/ECO NUMBER	APPVD DATE	SCALE NONE	RELEASED DATE 9/14/19	REVISION DATE 9/14/19	REV. NO.	SHEET 1 OF 1
- CAD DRAWING - MANUAL REVISIONS NOT PERMITTED							

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JKL Components:](#)

[ZM-180-CW](#)