


165° WIDE BEAM LED CHANNEL for MEDIUM or LARGE SIGN BOXES

FEATURES

24V DC
IP67
50,000 Life Hours/5 Year Warranty
115 lm/W High Efficacy
Operating Temperature -20°C to +50°C
165° Wide Beam
20 Modules Per Strand

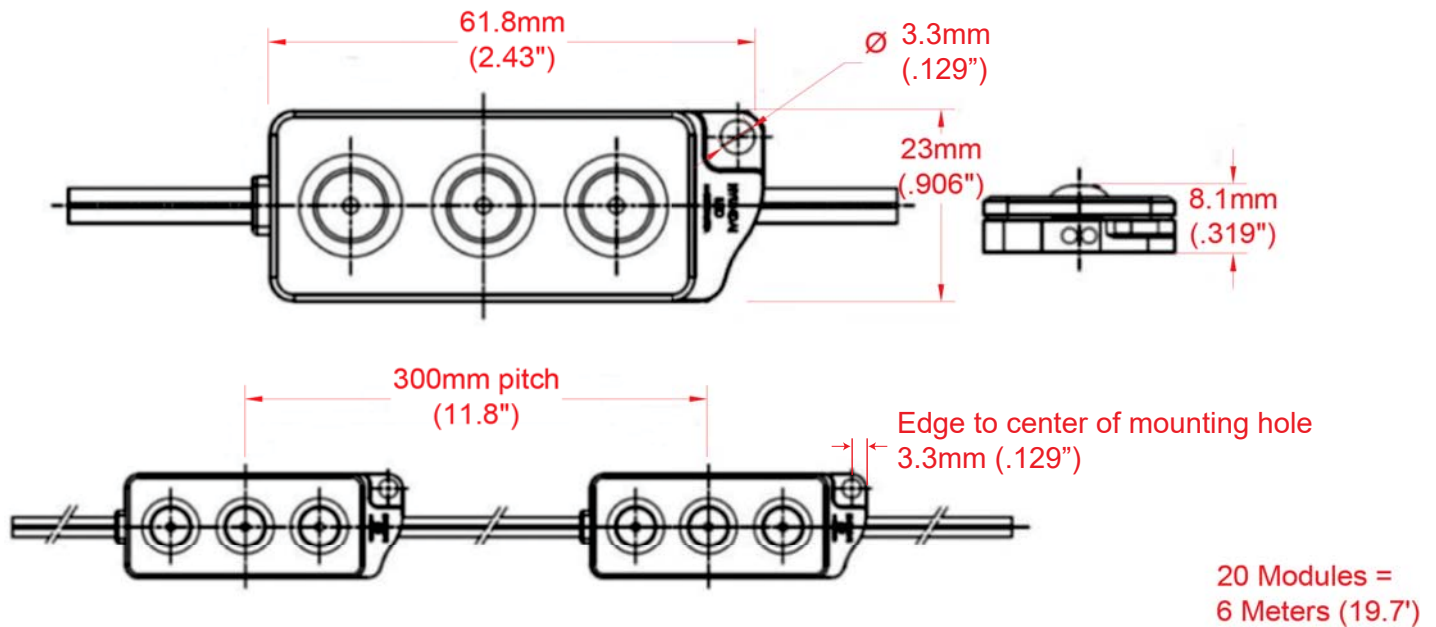


NOTES:

1. Mounting can be accomplished with double sided tape that is on the backside of modules. Screw holes are also present.
2. Wire with Red Stripe is Positive Input.
3. Use no more than 20 modules in series.
4. Take care to prevent exposed wire on the ends.

CAUS
E339601

JKL Part Number	Input Voltage	Power per Module	CCT	Beam Angle	CRI	Lumen Flux Per Module	Lumen Efficacy	No. Modules Per a Pack
ZM-359-CW	24V DC	1.6 W	6500K	165°	Ra80	185 lm	115 lm/W	20/6 Meters

			<div>METRIC</div> <div></div> <div>THIRD ANGLE PROJECTION</div>	<div>DIMENSIONS ARE IN mm (INCHES)</div> <div>TOLERANCE UNLESS OTHERWISE SPECIFIED</div> <div>1 PL +/- REF. 2 PL +/- REF. ANGLE +/-</div>	<div>JKL COMPONENTS CORPORATION</div> <div>TITLE</div> <div>WIDE BEAM LED CHANNEL MODULE</div>					
A	ADDED DIMENSIONS	3/8/22	DRAWN BY	APPV'D BY	DATE	SIZE	FSCM NO.	DRAWING NO.	ZM-359-CW	
	RELEASED	9/15/19	L. WENGSTROM	S.C.	9/15/19	A	55335			
REV. NO.	DESCRIPTION/ECO NUMBER	APPV'D DATE	- CAD DRAWING - MANUAL REVISIONS NOT PERMITTED			SCALE	RELEASED DATE	REVISION DATE	REV. NO.	SHEET
						NONE	9/15/19	3/8/2022	A	1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[JKL Components:](#)

[ZM-359-CW](#)