


Jumpers

151-8010, 151-8011, 151-8013

KOBI CONN

Jumpers

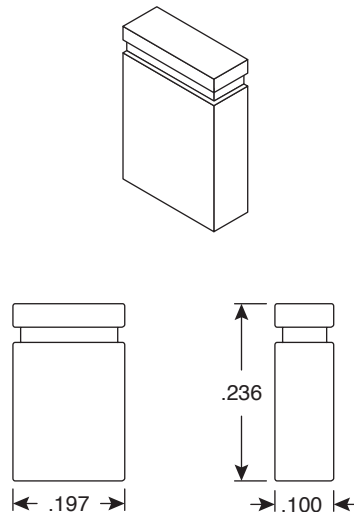

Dimensions: In.

SPECIFICATIONS	
Type:	Closed top
Contact Resistance:	30mΩ @ DC 100mA
Insulation Resistance:	1000MΩ min. @ 500VDC
Dielectric Withstand Voltage:	500VAC for 1 minute
Current Rating:	1A
Body:	PBT & glass reinforced fiber
Contact:	Gold plated phosphor bronze
Color:	Black (151-8010), Blue (151-8011), Red (151-8013)
Insertion Depth:	4.5mm (.177 IN)
Operation Temperature:	-55°C to +140°C

Date Last Revised: 10-18-05

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC- 300068

151-8010, 151-8011, 151-8013

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobiconn:

[151-8010](#) [151-8011](#) [151-8013](#)