

A13-117



FEATURES

* RATING:

Input: 12V/24V DC

USB output:

A13-117: 5V DC 0.5A max.

A13-117C: 5V DC 1A max.

A13-117D: 5V DC 2.1A max.

* MATERIAL

Housing: ABS (UL 94-HB).

Top contact: nickel plated metal.

Spring contact: nickel plated steel.

 


* Short circuit protection.

* Over voltage protection.

* Reverse protection.

* With 2A mini blade fuse max.

* Green LED indicator.

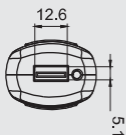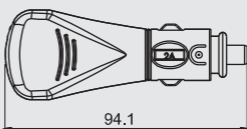

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[A13-117](#) [A13-117C](#) [A13-117D](#)