

A13-164



FEATURES

* RATING:

Input: 12V/24V DC

USB output:

A13-164: 5V DC 2.1A max,
1 or 2 ports.

A13-164D: 5V DC 2.5A max,
1 or 2 ports.

A13-164E: 5V DC 2.4A/2.4A max,
each port.

* MATERIAL

Housing: ABS (UL 94-HB).

Top contact: nickel plated metal.

Spring contact: nickel plated metal.

* Suitable for most mobile phones and consumer electronic devices.


* Heat sinks on the housing for efficient heat dissipation.

* Short circuit protection.

* Over voltage protection.

* Green LED indicator.

* With 3A mini blade fuse max.

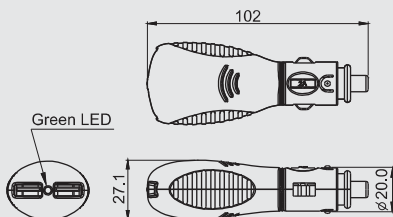

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[A13-164D](#) [A13-164E](#)