

A13-177/ 177B



FEATURES

* RATING:

Input: 12V/24V DC

USB output:

A13-177: 5V DC 2.1A max, 1 or 2 ports.

A13-177B: 5V DC 2.1A+2.1A max, 2 ports.

Socket output: 10A max.

Total output: 10A max

* MATERIAL OF SOCKET

Housing: ABS (UL 94-HB).

Inner contact: nickel plated metal.

Contact: nickel plated metal.

* MATERIAL OF PLUG

Housing: phenolic (UL 94V-1).

Top contact: nickel plated brass.

Spring contact: nickel plated spring steel.

* 0°~180° adjustable plug.

* One outlet socket with light ring.


* Dual USB ports suitable for most mobile phones and consumer electronic devices.

* Short circuit protection.

* Over voltage protection.

* With 10A glass tube fuse max.

* Outlet socket fits with \varnothing 21mm plugs

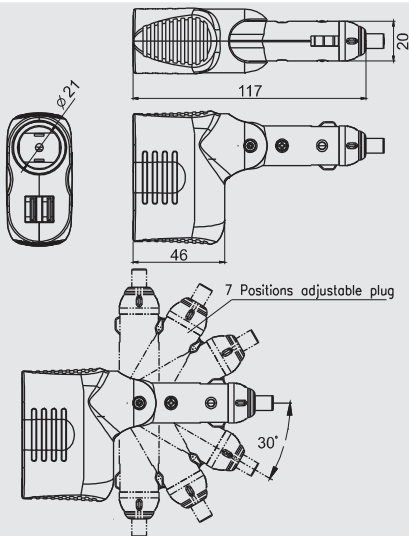

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[A13-177](#)