

# A13-215



## FEATURES

### \* RATING:

Input: 12V/24V DC

USB output: 5V DC 2.1A max,  
1 or 2 ports.

Socket output: 10A max

### \* MATERIAL

Housing: ABS (UL 94-HB).

Top contact: nickel plated metal.

Spring contact: nickel plated spring steel.

\* One outlet socket with dust-proof cap.

\* Dual USB ports suitable for most mobile phones and consumer electronic devices.

\* Short circuit protection.


\* Over-voltage protection.

\* Red LED indicator.

\* With 5A glass tube fuse max

\* Outlet socket fits with  $\varnothing$  21mm plugs

\* Housing color: white / black.

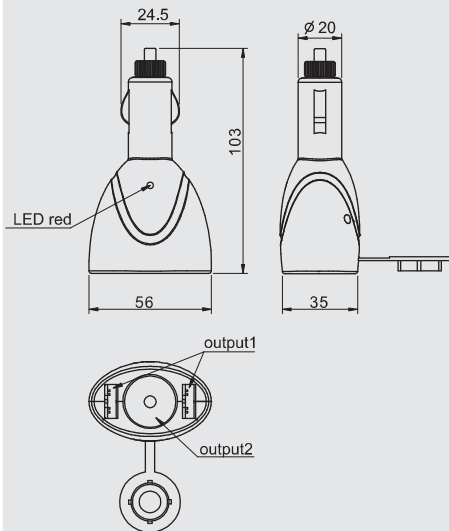

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[A13-215](#)