


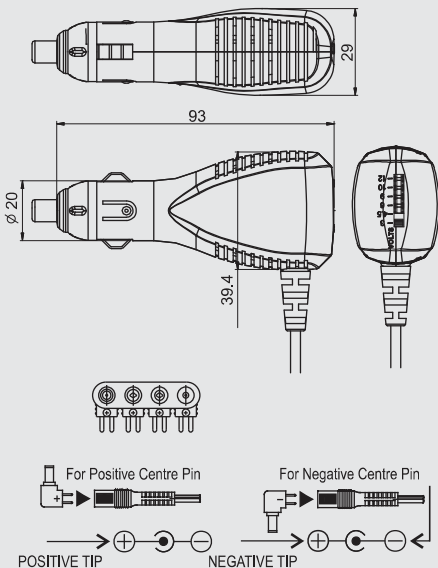

FEATURES

- * RATING: 12V-24V DC
- * Output: 3V/4.5V/6V/9V/10V/12V DC
2.5 A.
- * MATERIAL
Housing: PC (UL 94V-2).
Top contact: nickel plated metal.
Spring contact: nickel plated spring steel.
- * For powering battery-operated electronic devices up to 2.5A.
- * Illuminated voltage selection for night time use.
- * Short circuit protection.
- * Lead: 6 feet long, 18 AWG, with changeable TIP adapter plugs to suit small electronic applications.
- * Without fuse.



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[A13-148](#)