



FEATURES

* RATING

Input:

A13-152A1: 100V-240V AC 50/60Hz.

A13-152A4: 120V-240V AC 50/60Hz.

Output: 12V DC 1000mA

* MATERIAL

Housing: ABS (UL 94-HB).

* **A13-152A1**: with US adapter plug..

* **A13-152A4**: with EU adapter plug.

* Double insulation meets the requirement of class B EMI standard.

* Auto restart for short circuit protection.

* Outlet socket fits with \varnothing 21mm plugs.


* With LED power indicator.

* Meets ESD testing requirement for over 15KV.




A13-152A4

A13-152A1

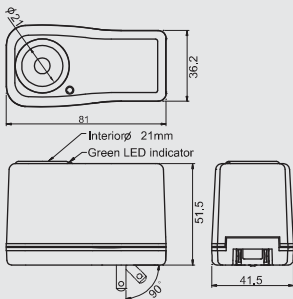

A13-152A4

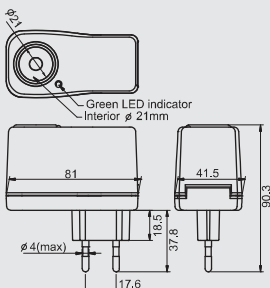

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[A13-152A1](#) [A13-152A4](#)