
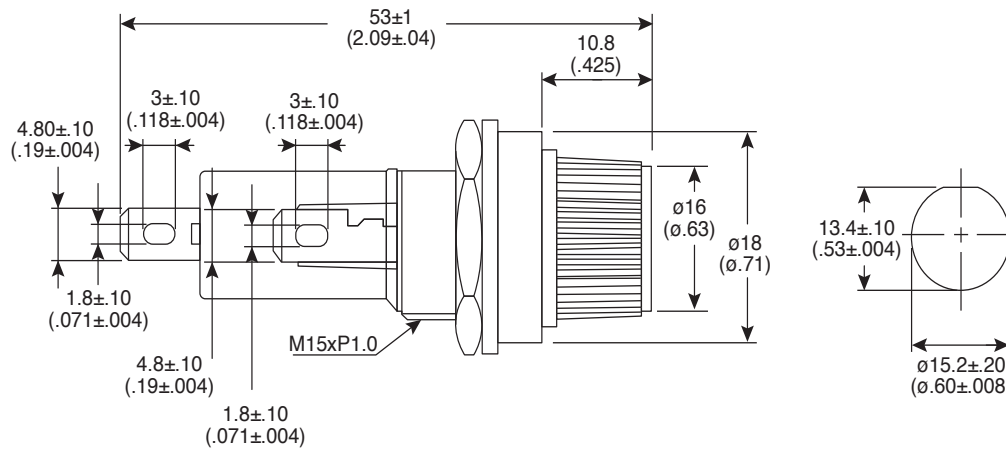


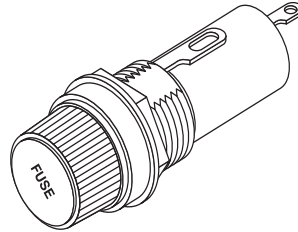

**Dimensions: mm (in.)**

| SPECIFICATIONS              |                                     |
|-----------------------------|-------------------------------------|
| Rating:                     | 10A/250VAC                          |
| Insulation Resistance:      | 500VDC 100MΩ Min.                   |
| Dielectric Strength:        | 1500VAC for 1 minute                |
| Fuse Size:                  | ø6.0x30mm ø6.35x31.8mm              |
| Type:                       | Standard panel mount for 1/4" fuses |
| Cap Color:                  | Black                               |
| RoHS Compliant by Exemption |                                     |

**Available from Mouser Electronics**  
**1-800-346-6873 / [www.mouser.com](http://www.mouser.com)**

EPD-200564

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eagle Plastic Devices:

[441-R3-13-GRX](#)