


DIMENSIONS: mm

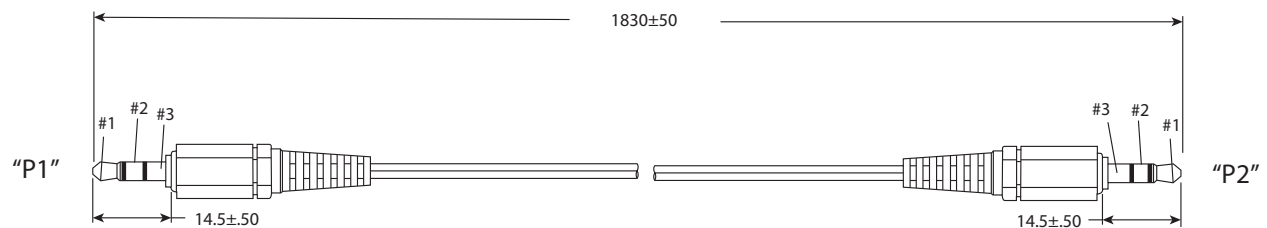

| CONNECTION | |
|------------|------------|
| P1 | WIRE COLOR |
| 1 | RED |
| 2 | WHITE |
| 3 | SPIRAL |

Specifications:

- Operating Temperature: -10°C ~ +80°C
- Insulation Resistance: DC/250V, 10MΩ Min.
- Withstand Voltage: AC/250V 2mA For One Minute.
- Tensile Strength: Overmold to cable jacket shall withstand 3kgf pull min. for one minute.

Notes:

- RoHS Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[172-181182-E](#)