


DIMENSIONS: mm

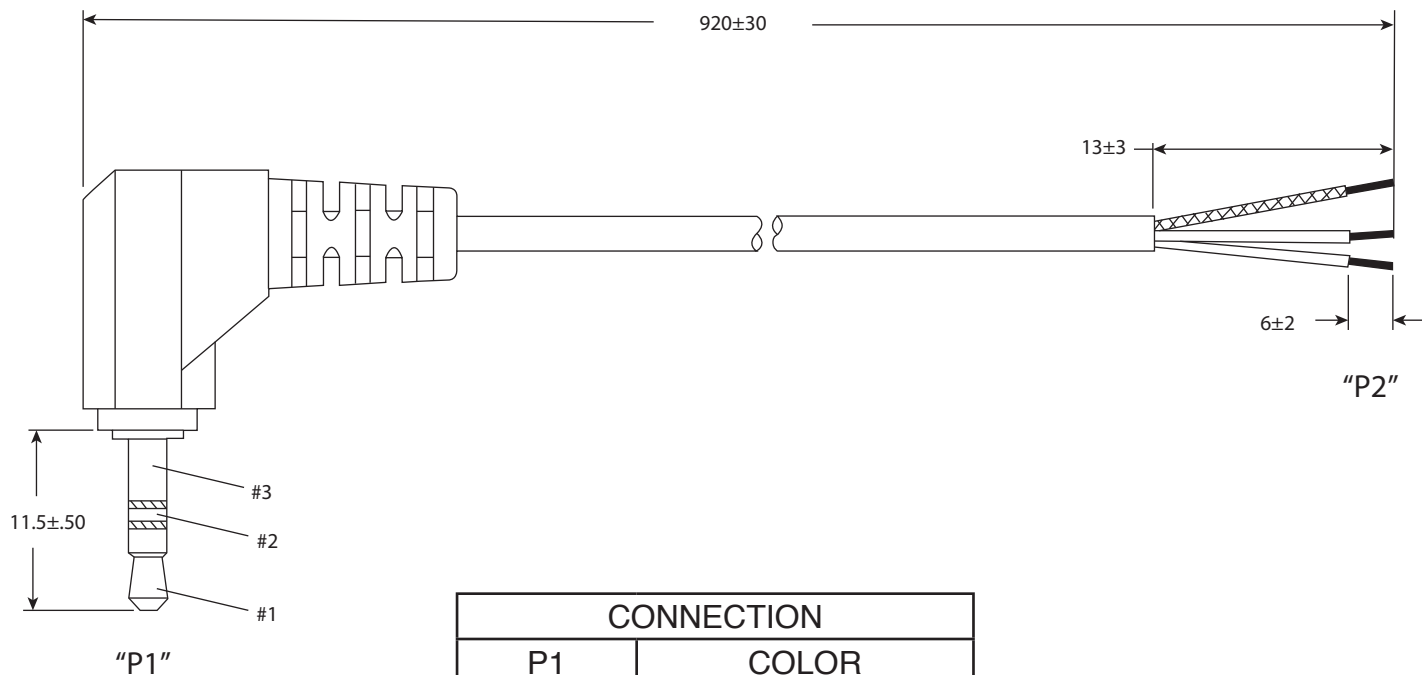

CONNECTION	
P1	COLOR
1	WHITE
2	RED
3	SPIRAL

Specifications:

- Operating Temperature: $-40^{\circ}\text{C} \sim +85^{\circ}\text{C}$
- Insulation Resistance: DC/250V ,10M Ω MIN.
- Withstand Voltage: AC/250V ,5mA For One Minute.
- Continuity Resistance: 3 Ω MAX.
- Continuity Test: 100%
- Tensile Strength: PHN/M/2.5 Overmold to cable shall withstand 2Kgf Pull MIN. For one minute.

Notes:

- RoHS Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[172-181185-E](#)