


DIMENSIONS: mm

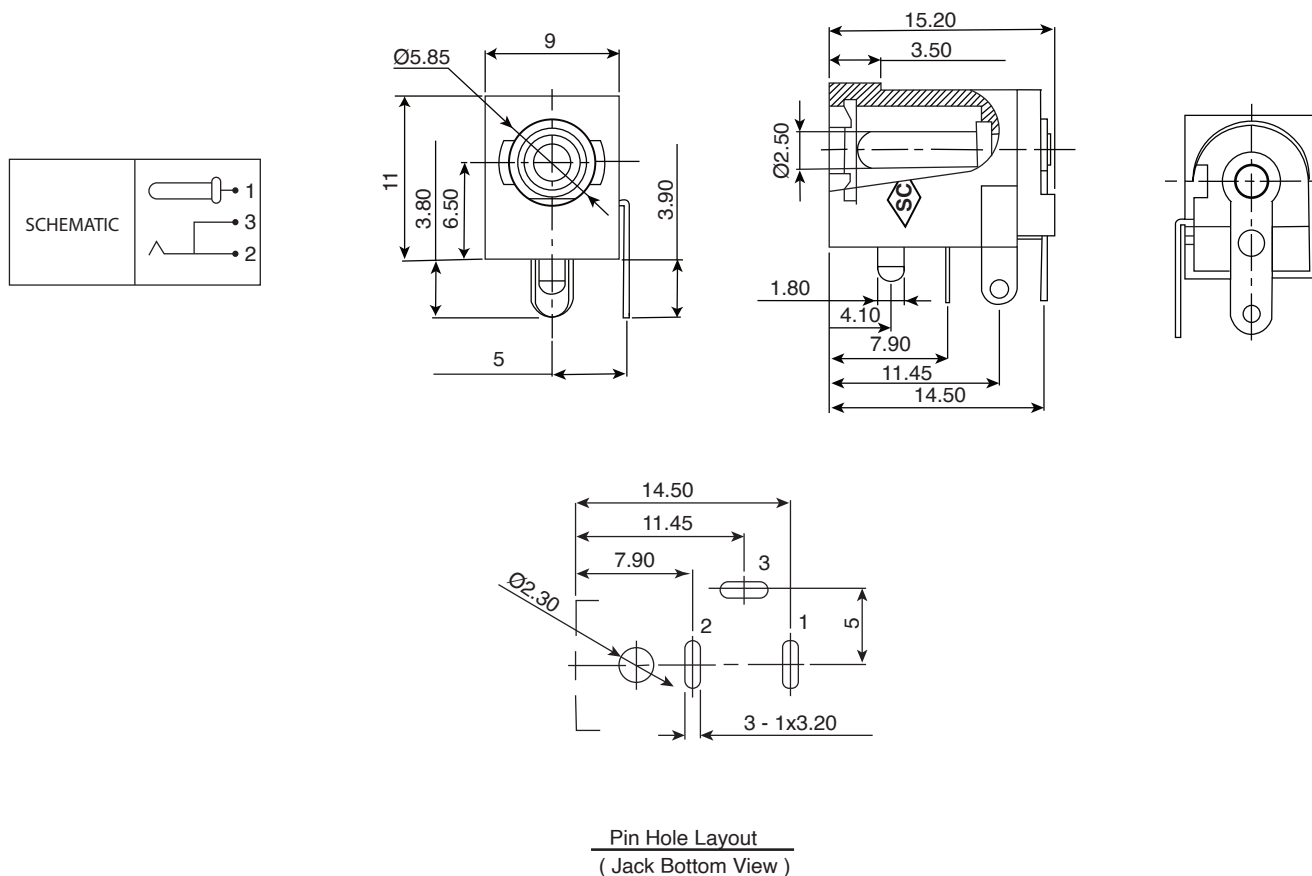

SPECIFICATIONS:

- Contact Resistance: 30m Ω max
- Current Rating: 5A/24VDC max
- Insulation Resistance: 100M Ω min at 500VDC
- Dielectric Withstand Voltage: 500VAC for one minute.

Note:

- RoHS Compliant by Exemption

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[163-443DC-EX](#)