



DIMENSIONS: mm

Date Last Revised: 02/4/20

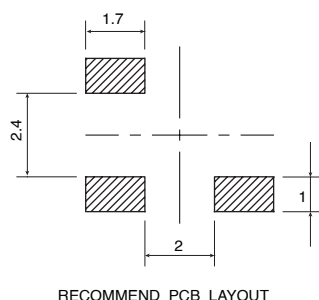

Frequency Response curve

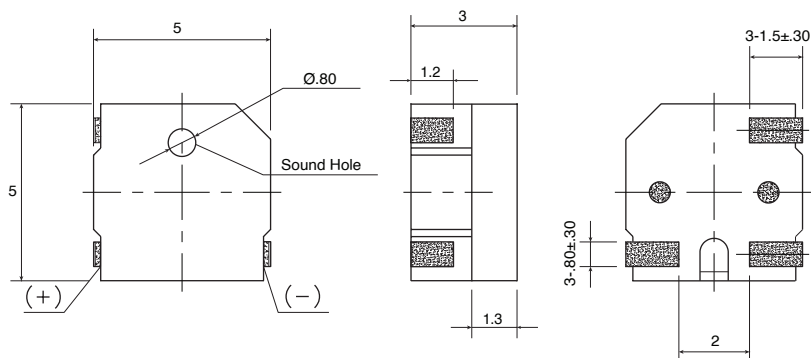

SPECIFICATIONS :

- Rated Voltage : 3V
- Operating Voltage : 2~4V
- Consumption : 110mA(Max)
- Sound pressure level (Distance at 10cm) : $\frac{77}{80}$ | 2600Hz dBA (Min)
- Direct Current Resistance : $12\Omega \pm 3$
- Rated Frequency : 2900Hz
- Operating Temp. : -20°C~+60°C
- Storage Temp. : -30°C~+80°C

Note: RoHS Complaint

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KT-400591

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-EMB503-RO](#)