



Terminals

159-1604, 159-6187, 159-6205

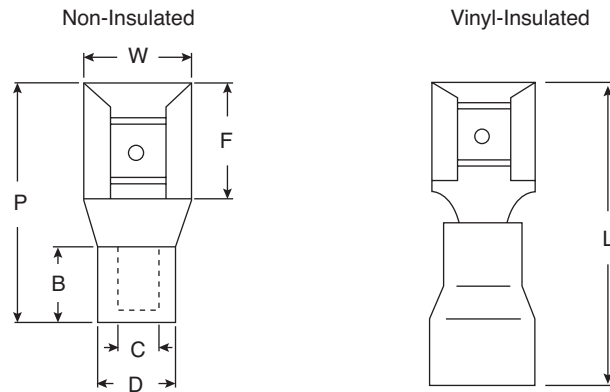

Terminals

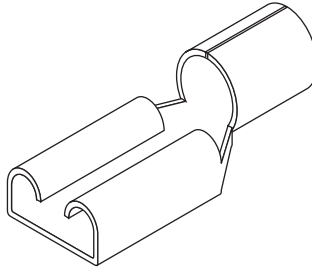

Dimensions: in.
(except where noted)

SPECIFICATIONS	
Wire range:	16 - 14 AWG (2mm ²)
Maximum electric current:	15 ampere
Maximum electrical rating:	75°C 300 volts max.
Insulation color:	blue
Terminal material:	brass
Double crimp	sleeve on barrel
Barrel dimension:	B= .197 (5.0mm) C= .091 (2.3mm) D= .130 (3.3mm)

Mouser Stock No.	NEMA Tab (in.)	Material Thickness (in.)	Dimensions (in.)			
			W	F	P	L
159-1604	.020 x .110	.012	.126	.256	.551	.732
159-6187	.020 x .187	.016	.197	.252	.551	.748
159-6205	.020 x .205	.014	.224	.260	.662	.728

Date Last Revised: 2-2-12

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300026

159-1604, 159-6187, 159-6205

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[159-6205](#) [159-1604](#) [159-6187](#)