


SMD Phone Jack

161-2622

KOBI CONN

SMD Phone Jack

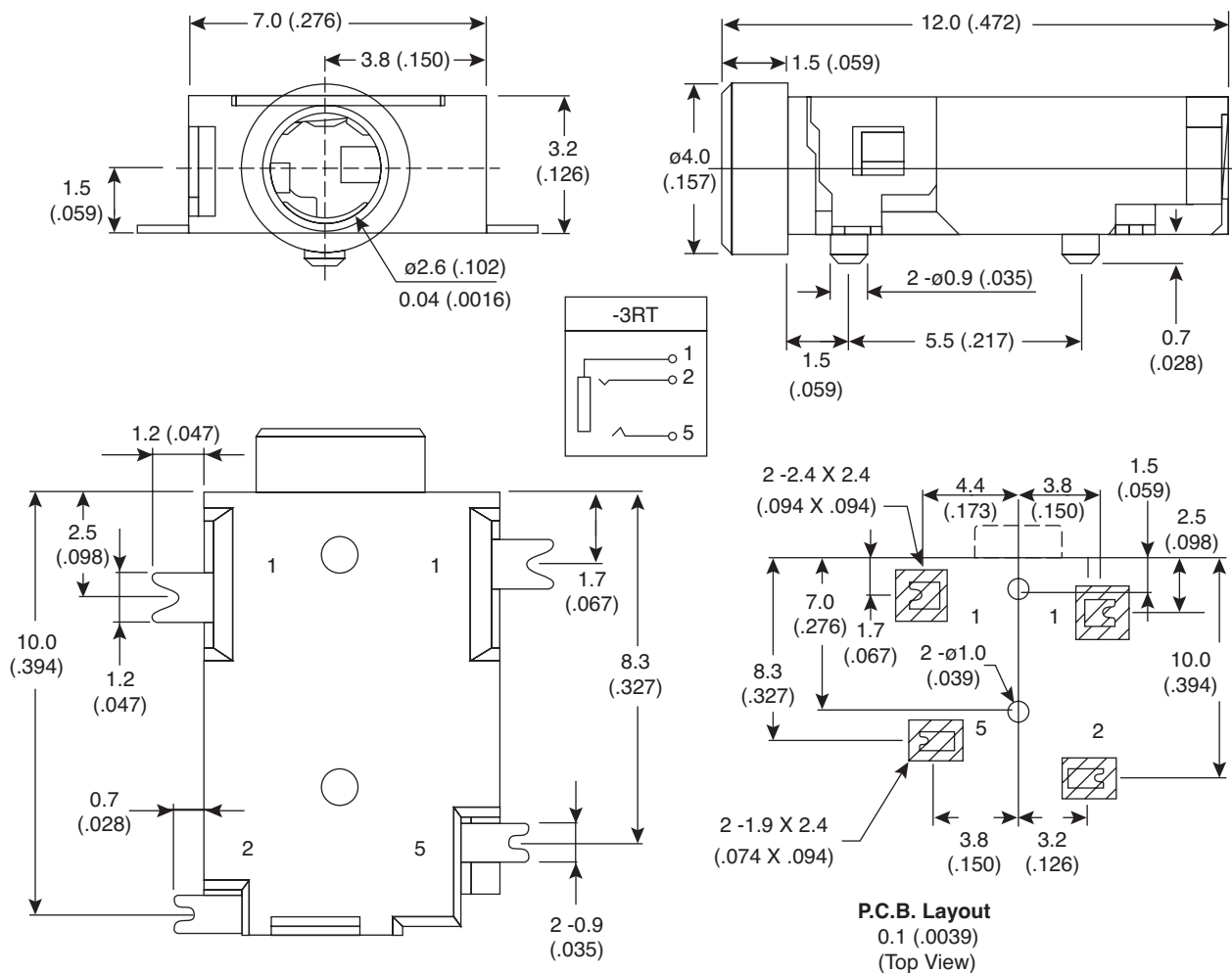

SPECIFICATIONS

Voltage rating:	16 VDC
Current Rating:	0.3 A
Contact resistance:	50 m ohm maximum
Insulation resistance:	100 M ohm minimum
Dielectric strength:	500 VAC for 1 min.
Durability:	5000 cycles
Insertion Force:	0.2Kg to 2.0Kg
Life cycle:	260°C for 5 seconds
Operating temperature:	-25°C to +85°C

TOLERANCE

X.	±0.5
X.X	±0.3
X.XX	±0.15

MATERIALS

Contacts:	Phosphor bronze
Housing:	Nylon-46 G30% black
Plating:	Gold flash

Date Last Revised: 6/26/12

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-300406

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

161-2622

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-2622](#) [161-2622/TR-E](#)