


# USB Connector B Type, Receptacle Right Angle & Single Deck (SMT)

154-UBR44-E



USB Connector B Type, Receptacle Right Angle & Single Deck (SMT)

154-UBR44-E

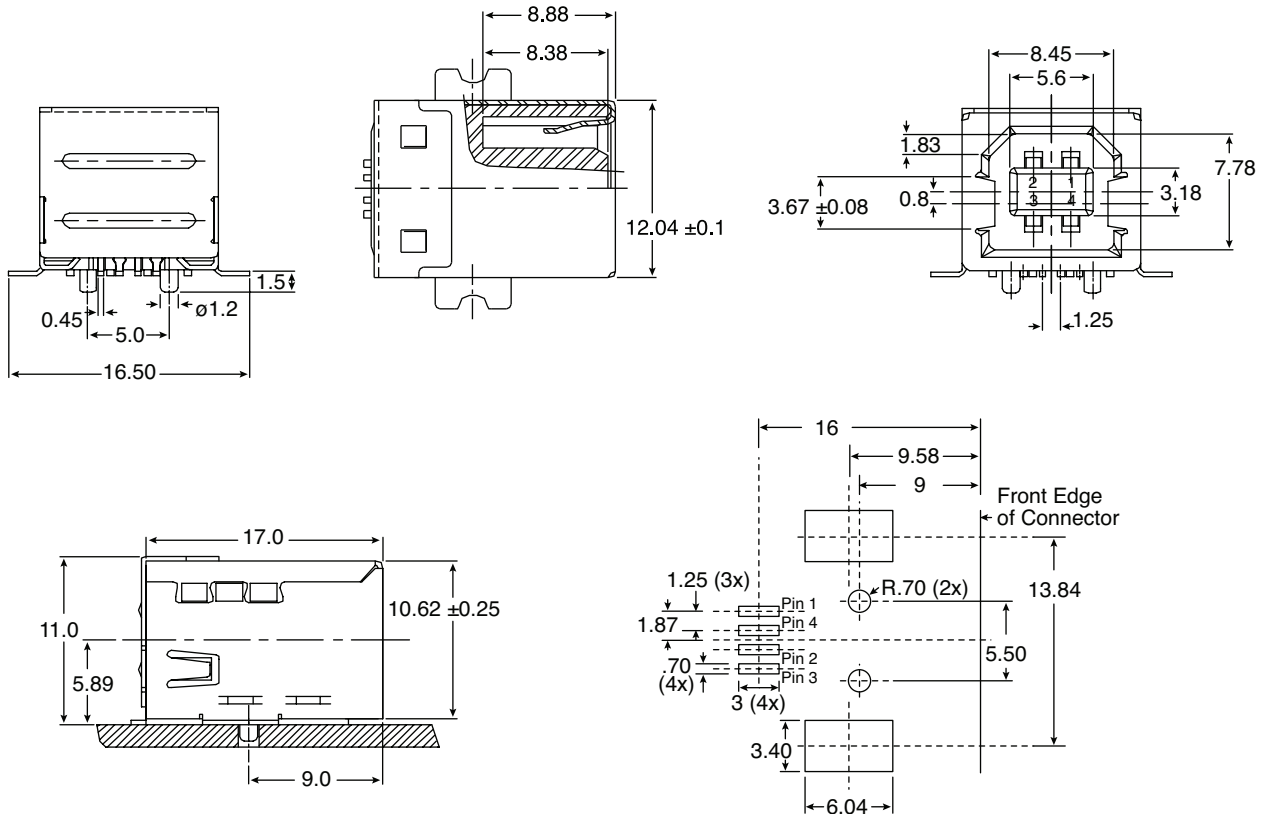

Recommended PCB Footprint

Dimensions: mm (in.)

Specifications	
Positions:	4
Insulator Color:	White
Contact Plating:	Au30u" or contact area Pd-Ni 30u" min and plated gold 2u" min on top
Shell Plating:	NI + TIN
Material of Insulation:	PA-6T
Voltage:	30 VAC (R.M.S.)
Current:	1.5 Ampere maximum per contact at 30°C T-Rise
Temperature:	-55°C to +85°C
Contact Resistance:	30 milliohms maximum initial
Insulation Resistance:	1,000 megohms minimum
Dielectric Withstanding Voltage:	500VAC at sea level
Recommended PC Board Thickness:	1.57mm
Allow For Panel Thickness Of:	2.67mm max if the receptacle conector is mounted behind a panel
RoHS Compliant	

Date Last Revised: 6-22-11

Available from Mouser Electronics  
1-800-346-6873  
www.mouser.com

KC-301007

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[154-UBR44-E](#)