
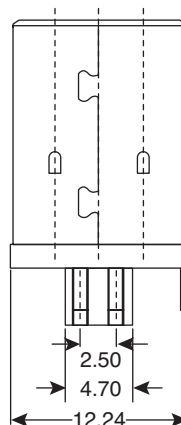
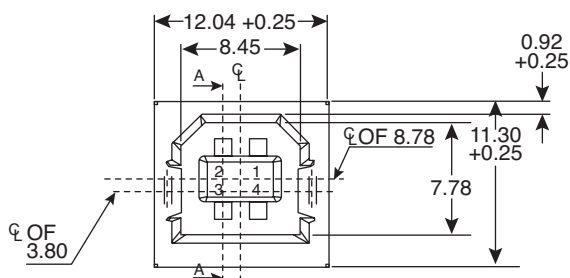
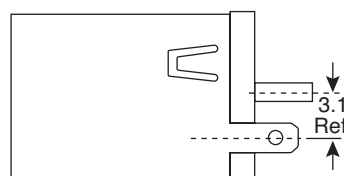
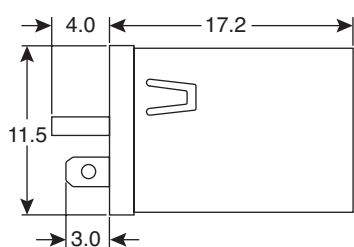


USB Connector B Type Receptacle and Solder Tail

154-UBW21-E

KOBICONN

USB Connector B Type Receptacle and Solder Tail

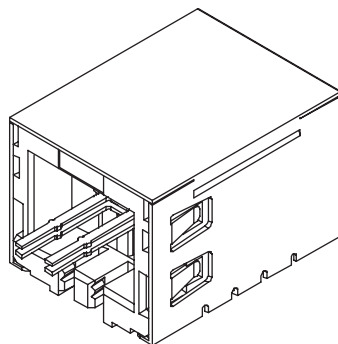

Dimensions: mm

Electrical Specifications	
Contact Resistance:	30 Milliohms max.
Dielectric w/standing Voltage:	750 VAC
Insulator Resistance:	1,000 Megohms min.
Capacitance:	2 picofarads max. @ 1KHz

Specifications	
Voltage:	39.2 Newtons max.
Current:	9.8 Newtons min.
Temperature:	-55°C to +85°C

Materials	
Shell:	Copper Alloy; Tin-Lead or gold plated over copper
Housing:	Thermoplastic, glass filled, 130°C
Contacts:	Copper Alloy; 5μ" gold plated
RoHS Compliant	

Date Last Revised: 7-19-06

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC-301020

154-UBW21-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[154-UBW21-E](#)