


USB "A" Mini-USB "B" Cable

172-1026-E

KOBI CONN

USB "A" Mini-USB "B" Cable

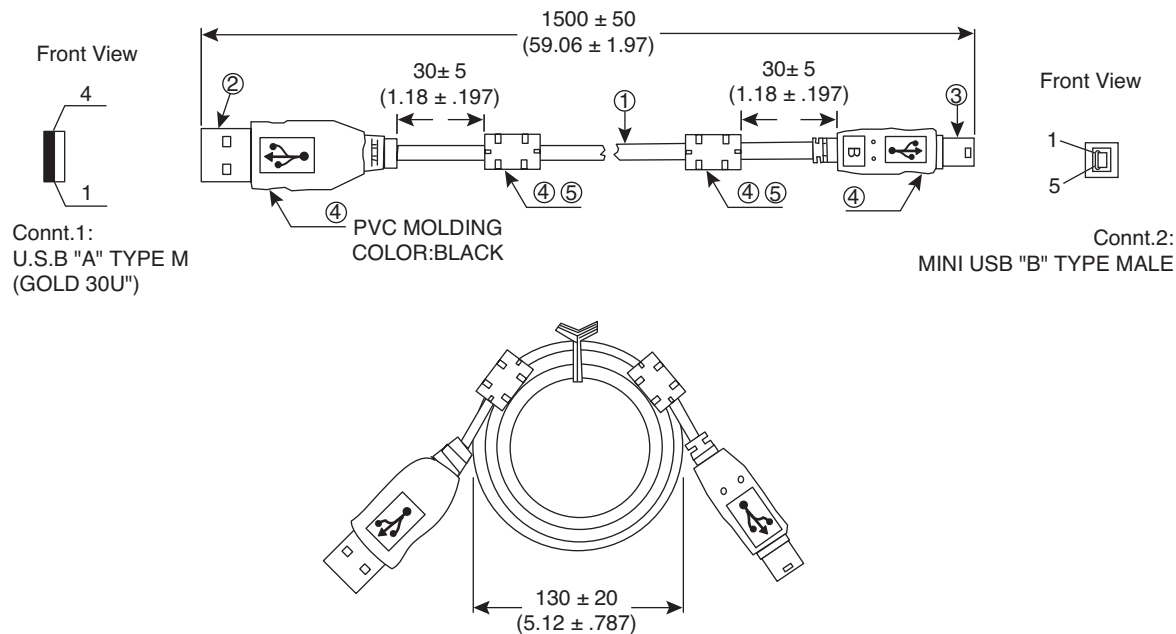

Dimensions: mm (In.)

SPECIFICATIONS	
(5) Ferrite Core:	ø12x25xø5.6mm
(4) PVC Molding:	black
(3) Connt. 2:	Mini USB "B" type 5P male
(2) Connt. 1:	USB "A" type male
(1) Cable:	28AWG/1P+28AWG/2C+AEB
	Rev: 2.0
	Jacket color: black
	OD: 3.8 ± 0.1mm
RoHS Compliant	

ELECTRICAL SPECIFICATIONS	
Contact resistance:	2Ω max
Insulation resistance:	50Mega Ω min.
Hi-pot:	300VDC/10ms
100% open short mis-wire test	

Date Last Revised: 8-22-06

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

KC- 301040

172-1026-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[172-1026-E](#)