
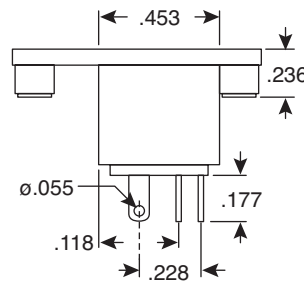
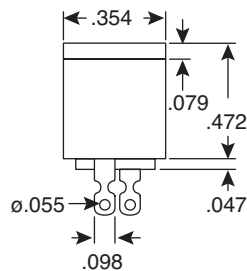
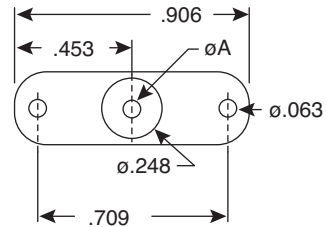
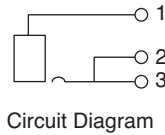


DC Power Jacks

163-5005-E, 163-5006-E

KOBICONN

DC Power Jacks

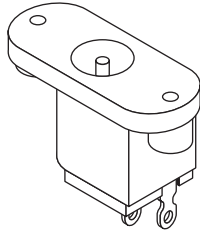

DIMENSIONS: in.
(Except where noted.)

SPECIFICATIONS

Type:	Molded with NC Switch
Center Pin:	A= 2.5mm (163-5005-E), 2.1mm (163-5006-E)
Terminals:	Silver Plated Brass
Shunt Spring:	Silver Plated Brass
Rating:	12V 1A
Tip Spring:	Silver Plated Copper Alloy
Insulation Resistance:	1,000MΩ
Contact Resistance:	30mΩ Max.
Extraction Force:	0.3kg ~ 2.0kg
Insertion Force:	0.3kg ~ 2.0kg
Withstand Voltage:	500VAC for 1 Minute
Life Time:	Withstand >5,000 cycles insertion & withdrawal with testing plug
Warning:	This product should not be washed by a chloride.
RoHS Compliant	

Date Last Revised: 6-22-07

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301048

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

163-5005-E, 163-5006-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[163-5005-E](#) [163-5006-E](#)