


# USB "A" Type Plug

154-UAW16-E, 154-UAC16-E



USB "A" Type Plug

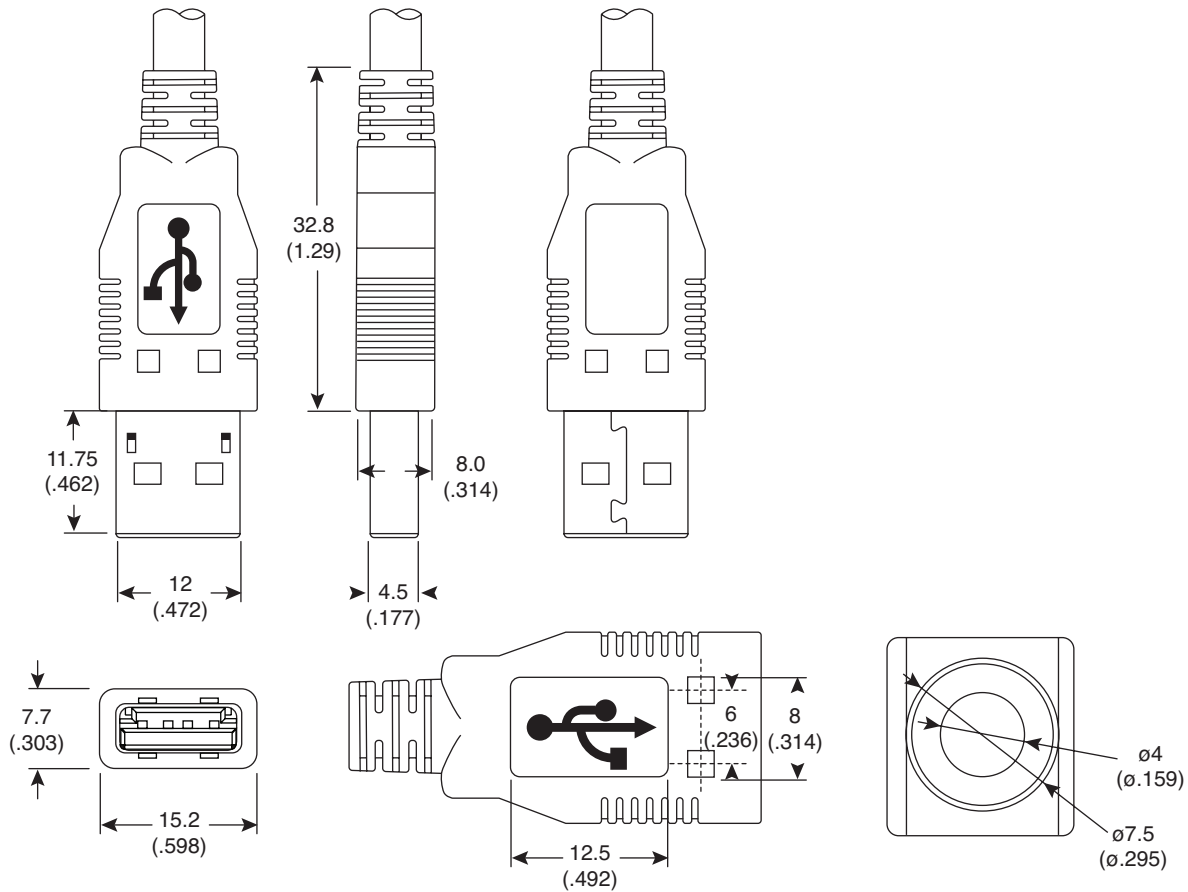

Dimensions: mm (In)

## MATERIAL SPECIFICATIONS: HOOD

<b>Hood Material:</b>	ABS Resin
<b>RoHS Compliant</b>	

## ELECTRICAL SPECIFICATIONS: PLUG

<b>Voltage:</b>	30 VAC
<b>Current:</b>	1.5A Max. per contact at 30°C Rise
<b>Temp. Range:</b>	Storage: 20°C to 60°C Operating: 0°C to 50°C
<b>Contact Resistance:</b>	30mΩ Max. Initial
<b>Insulation Resistance:</b>	6000MΩ Min. Initial
<b>Dielectric Withstanding Voltage:</b>	750 VAC at Sea Level
<b>RoHS Compliant</b>	

## MATERIAL SPECIFICATIONS: PLUG

<b>Upper and Lower Shell:</b>	Steel
<b>Housing:</b>	Thermoplastic, glass filled
<b>Contact:</b>	Copper Alloy
<b>Recommended Cable</b>	
<b>Application:</b>	O.D. $\phi 3.4\text{mm}$ to $\phi 5.3\text{mm}$
<b>All Parts Packaged Unassembled</b>	
<b>RoHS Compliant</b>	

Date Last Revised: 7-19-07

Available from Mouser Electronics  
1-800-346-6873 / www.mouser.com

KC-301153


154-UAW16-E, 154-UAC16-E

# USB "A" Type Plug


154-UAW16-E, 154-UAC16-E




USB "A" Type Plug

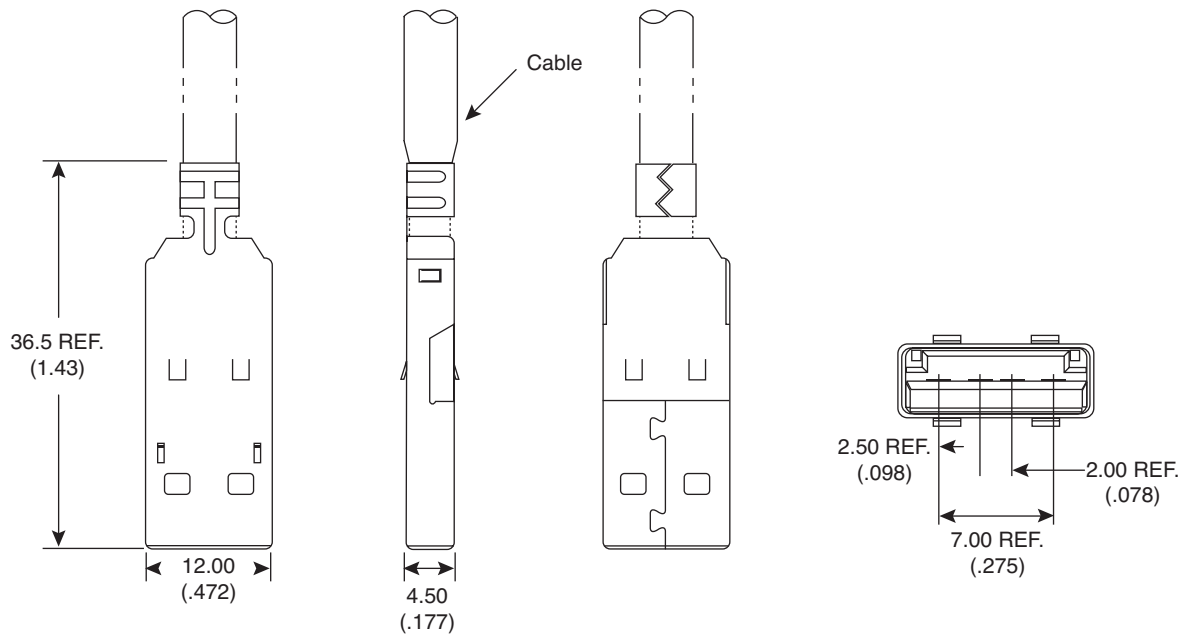

### Assembly Process

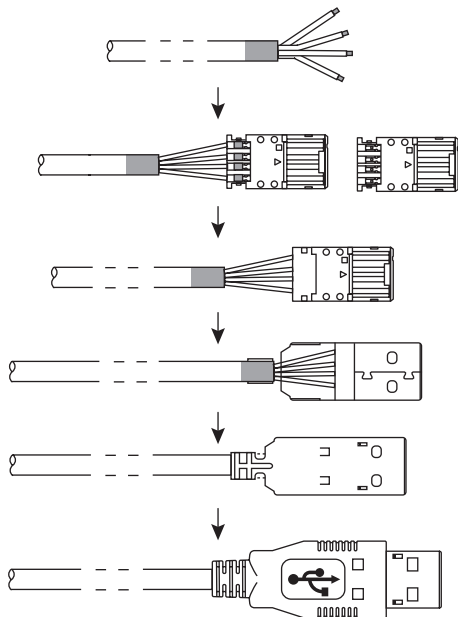

### Part

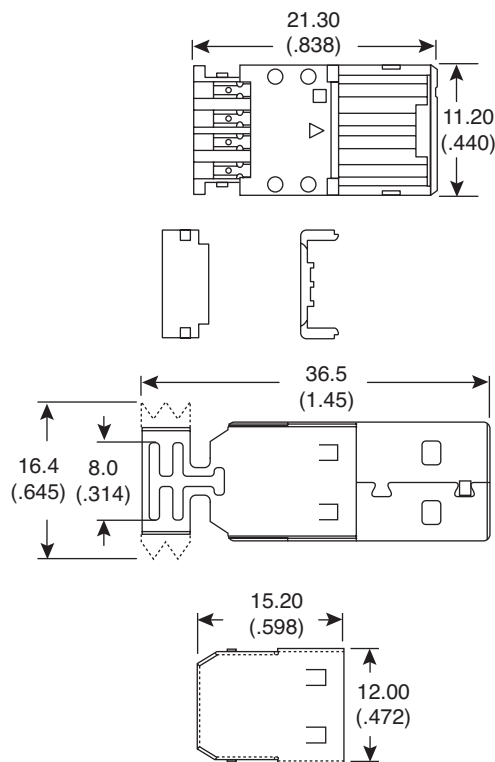

154-UAW16-E, 154-UAC16-E

Date Last Revised: 7-17-07

Dimensions: mm (In)

Available from Mouser Electronics  
1-800-346-6873 / [www.mouser.com](http://www.mouser.com)

KC-301153

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[154-UAW16-E](#) [154-UAC16-E](#)