


IEC 60320 C14 Inlet

161-R301B07-E

KOBICONN

IEC 60320 C14 Inlet

161-R301B07-E

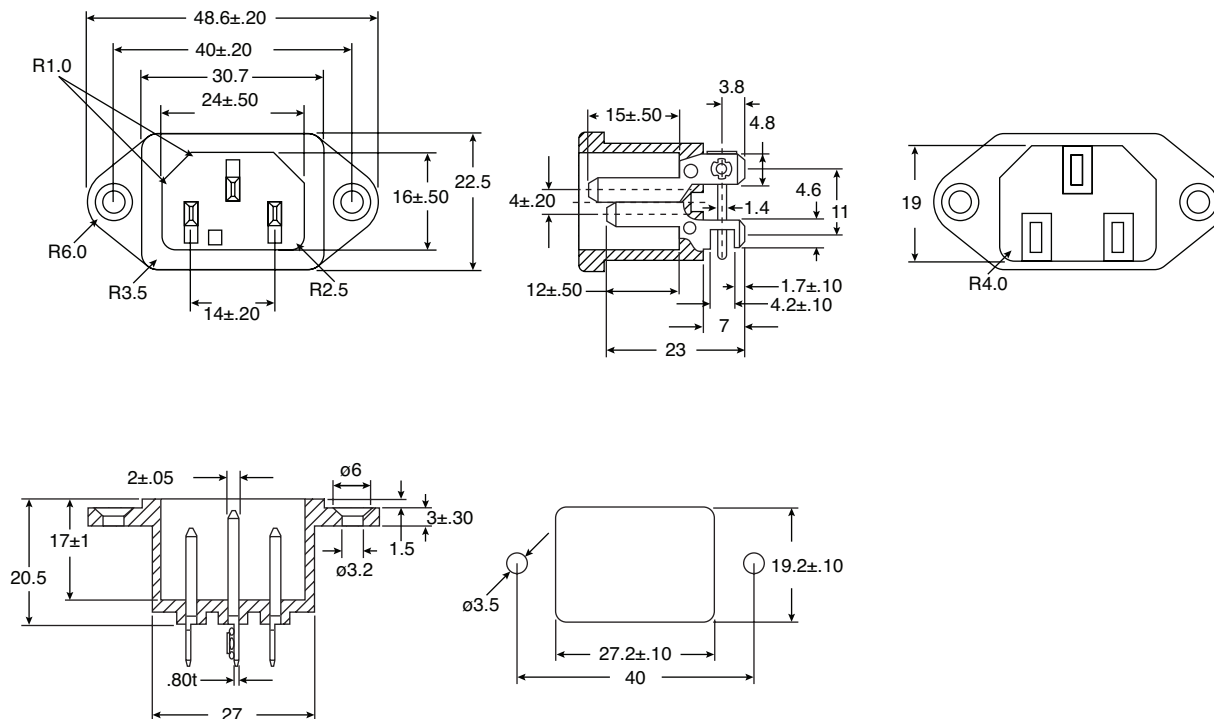

Dimensions: mm

SPECIFICATIONS

Rating:	10A, 250VAC
Insulation Resistance:	Over 100MΩ at 500VDC
Dielectric Strength:	2000VAC for 1 minute
RoHS Compliant	

Materials

Body:	Black Glass-Fiber Thermoplastic
--------------	---------------------------------

Tolerance

X.XX±0.1
XX.XX±0.2
XXX.XX±0.3

Date Last Revised: 8-20-07

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC- 301182

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-R301B07-E](#)