


HDMI Receptacle, Type C, Right Angle SMT

154-10412-E

KOBI CONN

HDMI Receptacle, Type C, Right Angle SMT

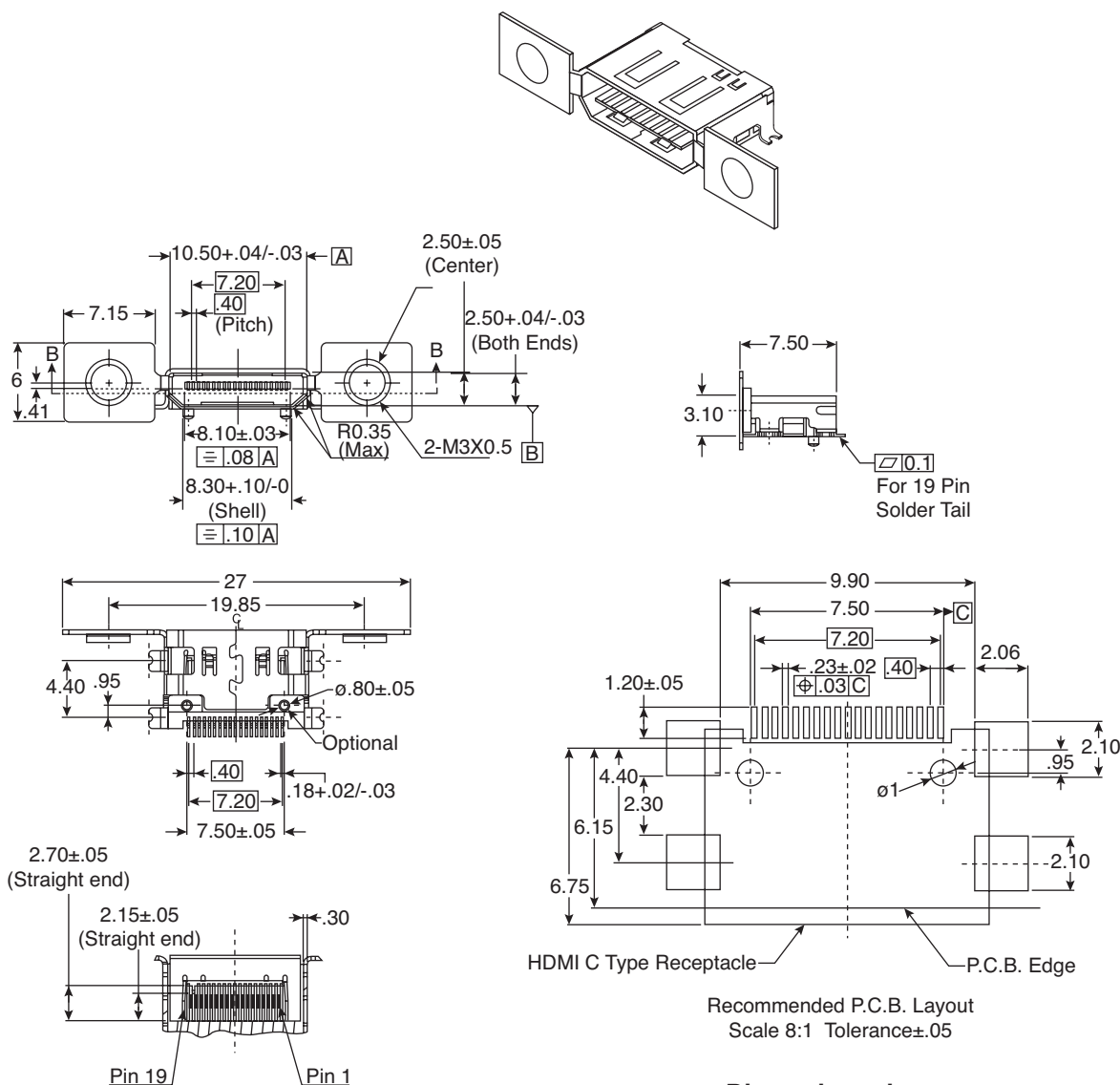

Dimensions: in.

SPECIFICATIONS

Current Rating:	0.5A
Voltage Rating:	40V DC
Contact Resistance:	10m Ω max.
Insulation Resistance:	100m Ω min.
Operating Temperature:	-25°C -185°C
RoHS Compliant	

MATERIALS

Housing:	High temp. plastic
Color:	Black
Shell / Terminal:	Copper alloy, Gold plating, underplating Nickel overall

Date Last Revised: 6-23-12

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301237

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

154-10412-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[154-10412-E](#)