


AC Power Cords

173-53101-E, 173-53102-E, 173-53121-E, 173-53103-E,
173-53122-E



AC Power Cords

173-53101-E, 173-53102-E, 173-53121-E, 173-53103-E, 173-53122-E

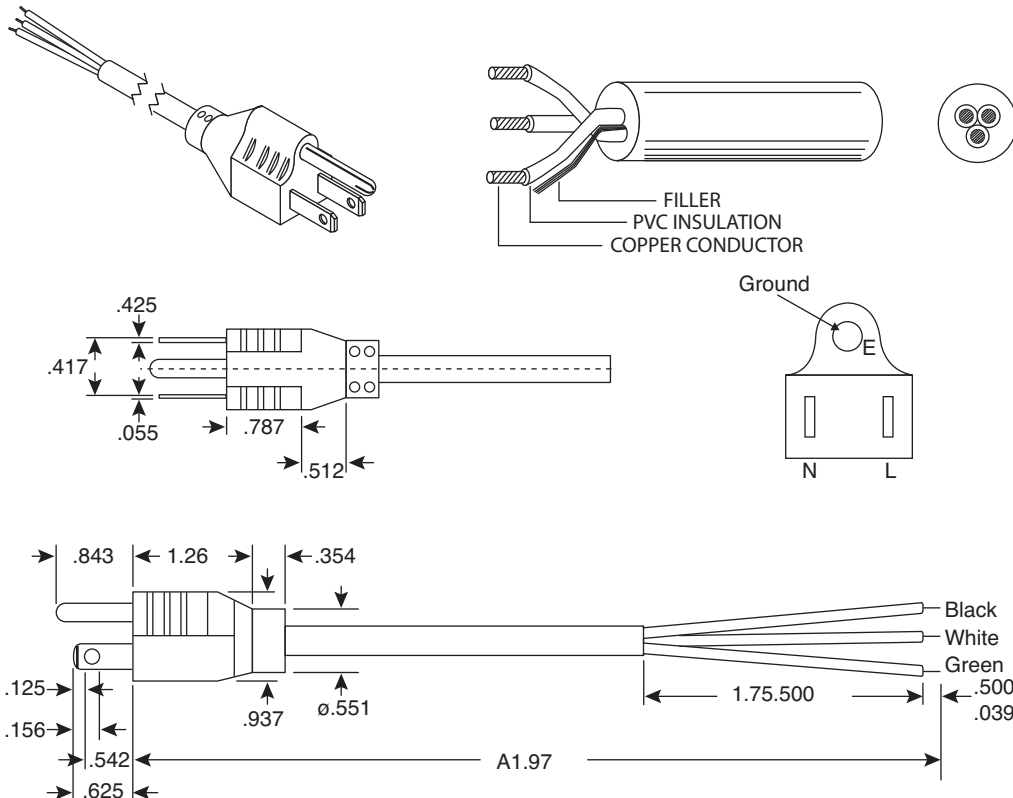

Dimensions: in.
(except where noted)

SPECIFICATIONS				
Temperature:	60°C			
Rated:	AWG	Voltage (VAC)	Current (A)	Power (W)
	18	125	10	1250
	16	125	13	1625
	14	125	15	1625
RoHS Compliant				

COLORS	
Black:	Hot Wire
White:	Neutral Wire
Green:	Ground

MOUSER STOCK NO.	Type of Conductor	Size AWG	Color	Length (ft)	Length (A)	Cord Jacket ø
173-53101-E	SVT	18/3	Black	6	72	.25
173-53102-E	SVT	18/3	Black	8	96	.25
173-53103-E	SVT	18/3	Black	10	120	.25
173-53121-E	SVT	18/3	Gray	6	72	.25
173-53122-E	SVT	18/3	Gray	10	120	.25

Date Last Revised: 08-15-08

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301308

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[173-53101-E](#) [173-53102-E](#) [173-53103-E](#) [173-53121-E](#) [173-53122-E](#)