


Extension Cable

172-7428-G-E

KOBI CONN

Extension Cable

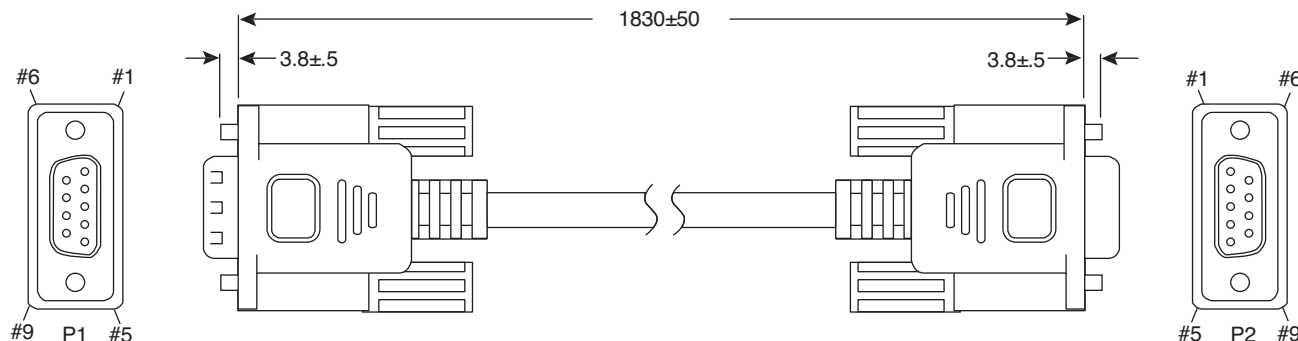

CONNECTION		
P1	WIRE COLOR	P2
1	BLACK	1
2	BROWN	2
3	RED	3
3	YELLOW	3
4	GREEN	4
5	BLUE	5
6	PURPLE	6
7	ORANGE	7
8	GRAY	8

Dimensions: mm

RoHS Compliant by Exemption

Electrical Specifications:

Operation Temperature:	-10°C - +80°C
Insulation Resistance:	DC/250V 5MΩ, for one minute.
Connection Resistance:	3.0Ω (Max)
Continuity Test:	100%

Mechanical Specifications:

Tensile Strength:	Overmold to cable jacket shall withstand 3kgf pull min. for one minute.
-------------------	---

RoHS Compliant

Date Last Revised: 06/04/09

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301347

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

172-7428-G-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[172-7428-G-E](#)