


Pogo Pin 1-Pos., 4.0x2.4x3.0mm

383-3M0H01

KOBICONN

Pogo Pin 1-Pos., 4.0x2.4x3.0mm

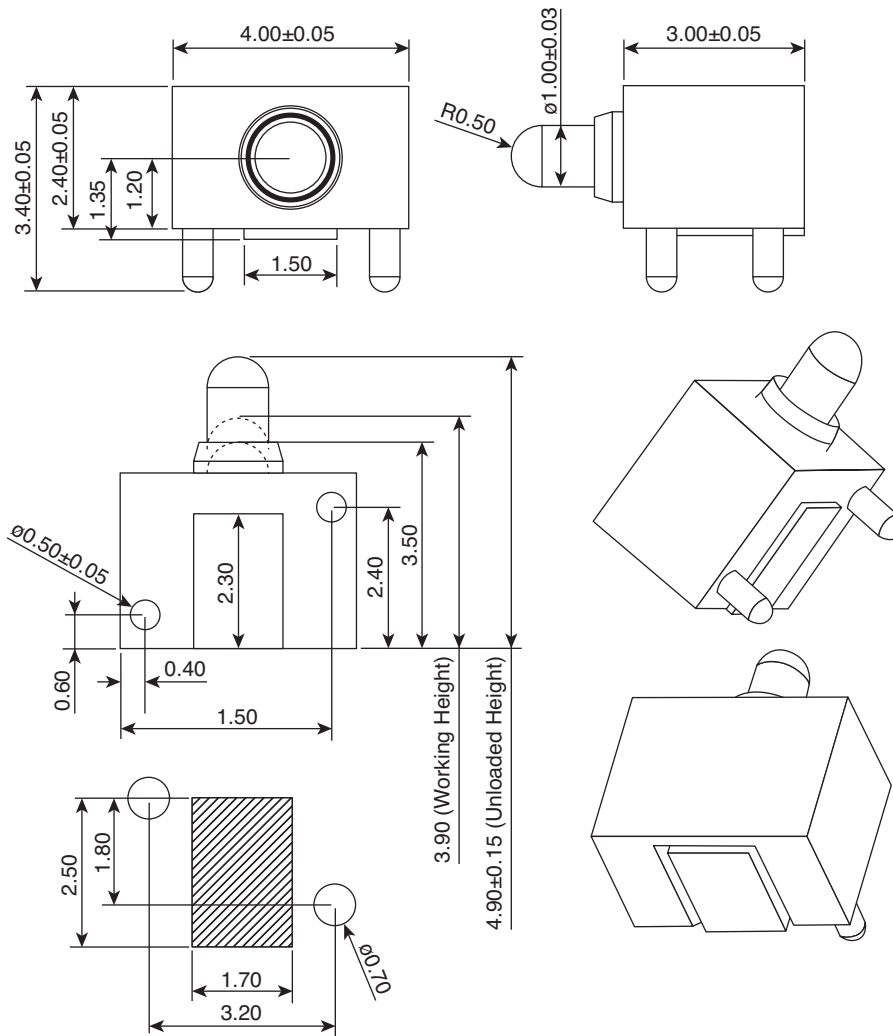

RECOMMENDED PCB LAYOUT

Dimensions: mm

Specifications	
Material	
Housing	Black HTN
Plunger & Barrel	Brass 3604
Spring	SUS 304
Plating:	
Contact Surface	10μ minimum Au over 50~100 μ Ni
Electrical	
Rated Current & Voltage	DC12V, 1A
Contact Resistance	50 mΩ maximum at working height
Mechanical	
Unloaded Height	4.90mm
Working Height	3.90mm
Spring Force	120g ± 20% at working height
Durability	10,000 cycles (minimum)

Date Last Revised: 6/29/12

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301348

383-3M0H01

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Shin Chin:](#)

[383-3M0H01](#)