


Part Number:

254-352-ROX

Piezoelectric Buzzer (External Drive)

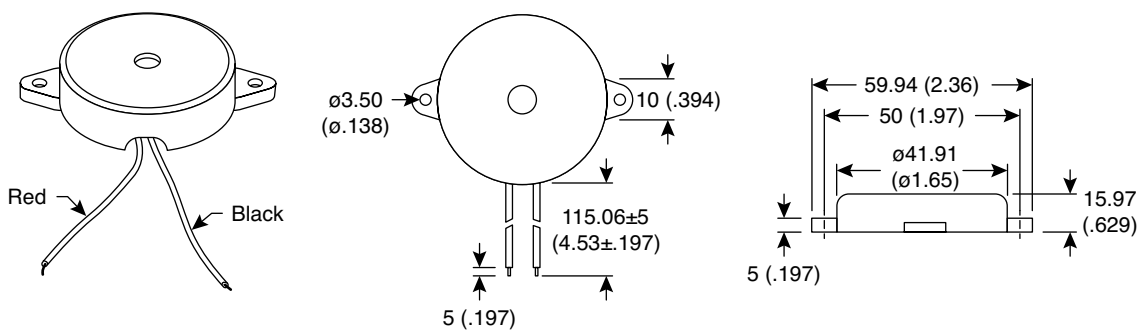

KT-400258

Mechanical Specifications:

- Operating temperature range: -20°~+60°C

Electrical Specifications:

- Sound pressure level: 90dB min. @ 2.5KHz, 9Vp-p, 10cm square wave;
80dB min. @2.5KHz, 1Vrms, 10cm sine wave
- Voltage: 30Vp-p max.
- Current: 3mA max. @ 9Vp-p square wave, 2.5KHz

Materials:

- Case top: polycarbonate
- Case bottom: ABS
- Lead wire: 28AWG
- Weight: 11.0g

Note:

- RoHS Compliant by exemption

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-352-ROX](#)