

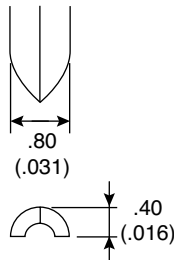
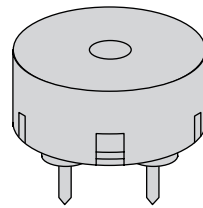


Part Number:


254-PB507-ROX

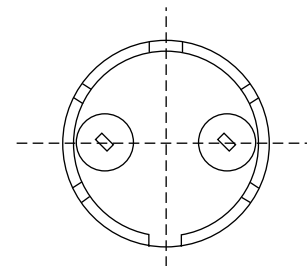

Pin Terminal

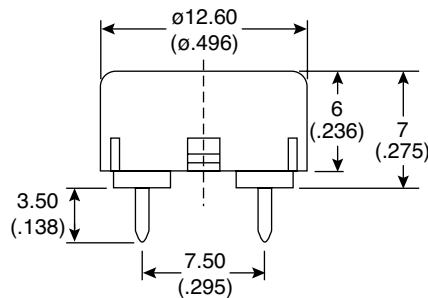

**Piezoelectric Buzzer
(External Drive)**

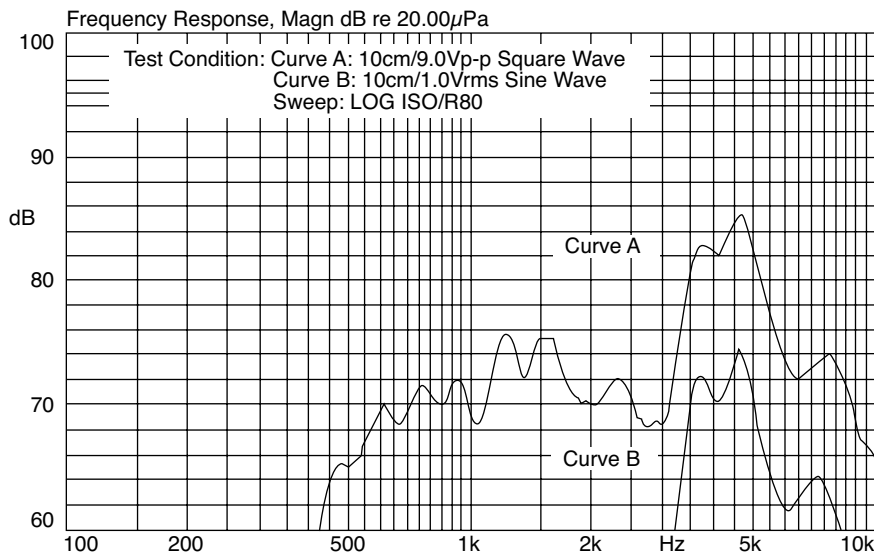

KT-400285

Electrical Specifications:

- Sound Pressure Level: 80dB min. at 4.0KHz/9.0Vp-p Square Wave/10cm.
70dB min. at 4.0KHz/1Vrms Sine Wave/10cm.
- Capacitance: 7,500pF ± 30% at 120Hz
- Current Consumption: 3mA max. at 4.0KHz/9.0Vp-p Square Wave
- Allowable Input Voltage: 15Vp-p max.

Mechanical Specifications:

- Operating Temperature: -20°C to +70°C
- Storage Temperature: -40°C to +85°C

Materials:

- Case: PBT
- Lead Pin: Phosphor Bronze
- Weight: 0.7 grams

Note:

- RoHS compliant by exemption

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-PB507-ROX](#)