


Part Number:

254-DR132-RO

Dynamic Receiver

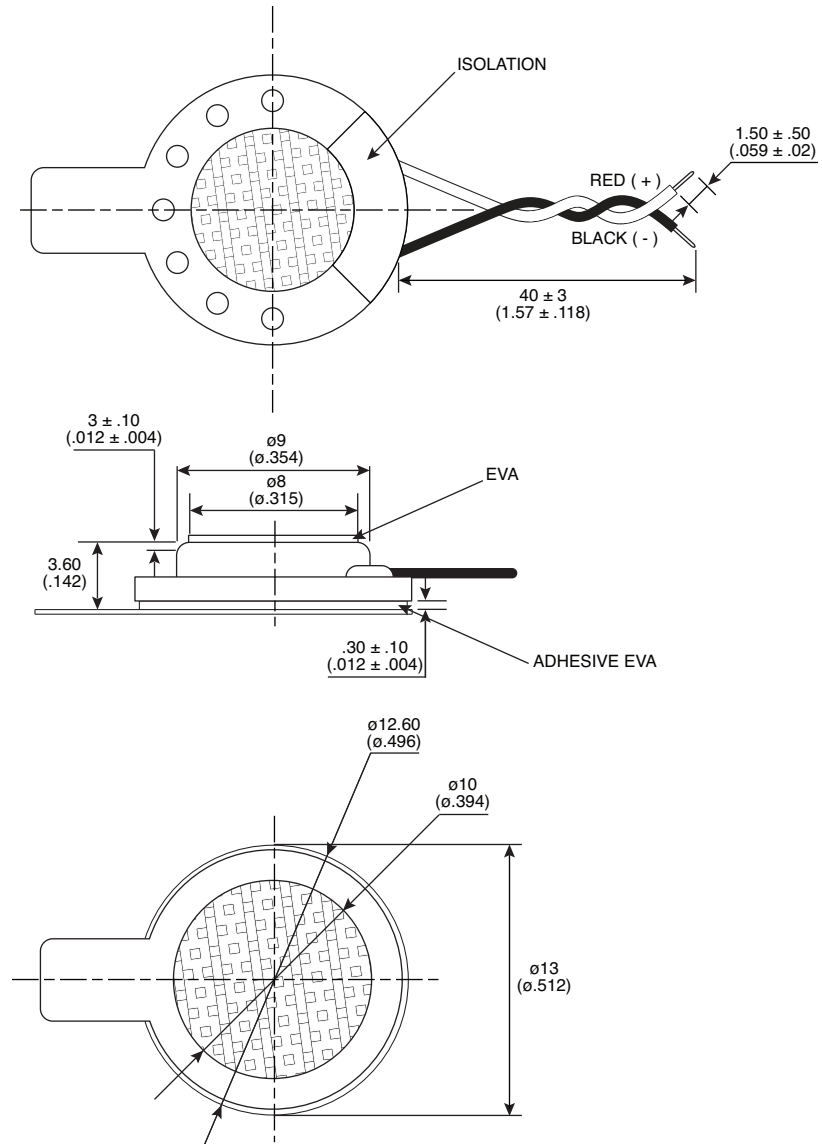

KT-400319

**Electrical Specifications:**

- Impedance:  $32\Omega \pm 15\%$
- Nominal Input Power: 10mW
- Max Input Power: 26mW for 1 minute
- Sensitivity: 115dB

**Materials:**

- Wire: AWG32
- Housing: Metal
- Diaphragm: PEI

**Note:**

- RoHS Compliant

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-DR132-RO](#)