



**Part Number:**

254-PB102-ROX

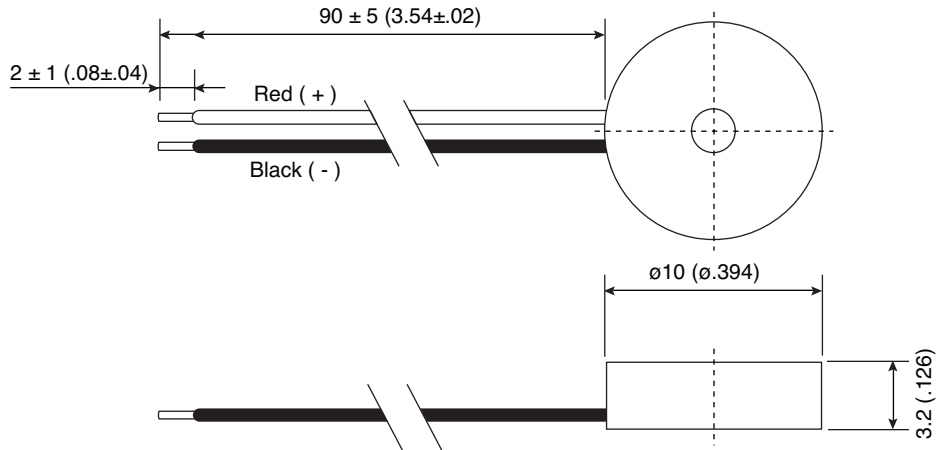

Piezoelectric Buzzer

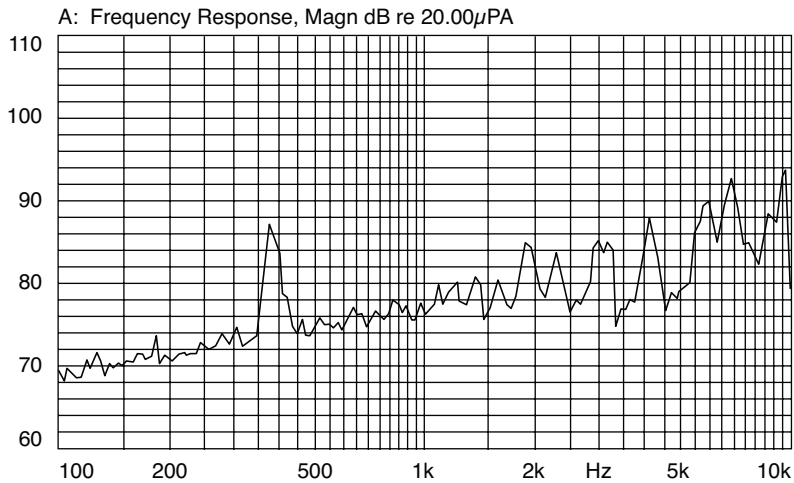

KT-400365

**Electrical Specifications:**

- Rated Voltage: 10 Vp-p
- Operating Voltage: 1~30 Vp-p
- Rated Current: 5mA(max)
- Sound Output at 10cm: 80dBA(min)
- Resonant Frequency: 3200Hz
- Capacitance: 11000pF  $\pm$  30% At 120Hz

**Mechanical Specifications:**

- Operating Temperature: -20°C ~ +60°C
- Storage Temperature: -20°C ~ +70°C

**Note:**

- RoHS Compliant by Exemption

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobitone:](#)

[254-PB102-ROX](#)