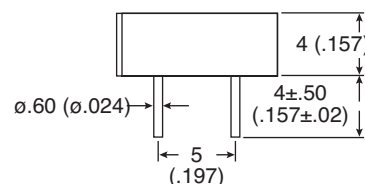
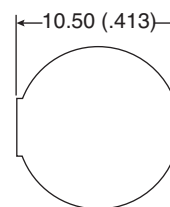
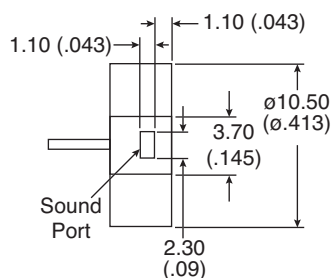
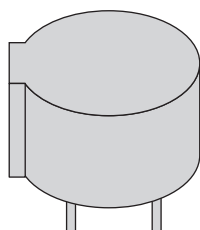


Part Number:

254-PB503-ROX


Frequency Response, Magn dB re 20.00μPa

Piezoelectric Buzzer
(External Drive)

KT-400405

Electrical Specifications:

- Sound Pressure Level: 72dB min. at 4.0KHz / 9.0Vp-p Square Wave / 10cm
- Capacitance: 9,500pF ± 30% at 120Hz
- Current Consumption: 3mA max. at 4.0KHz / 9.0Vp-p Square Wave
- Allowable Input Voltage: 15Vp-p max.

Materials:

- Case: PBT
- Lead Pin: Bronze
- Weight: 0.4 gms

Mechanical Specifications:

- Operating Temperature: -20°C to +70°C
- Storage Temperature: -40°C to +85°C

Note:

- RoHS compliant by exemption

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-PB503-ROX](#)